


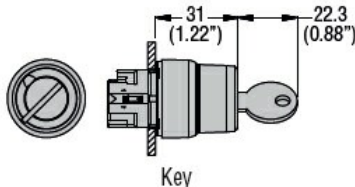

Product designation		Selector switch actuator key - 3 position	
Product type designation		LPSS33	
General characteristics			
Colour		Black	
Type of positions		1 - 0 - 2, key extraction in 1	
Material		Aluminium and zinc alloy	
IEC degree of protection		IP66, IP67 and IP69K	
Mechanical features			
Mechanical life		cycles	1000000
Fixing		Without mounting adapter	
Mounting adapter		LPXAU120M	
UL technical data			
UL degree of protection		Type1, 2, 3R, 4, 4X, 12, 12K	
Ambient conditions			
Temperature		Operating temperature	
		min	°C -25
		max	°C +70
		Storage temperature	
		min	°C -40
		max	°C +85
Dimensions			
			
Key			
Certifications and compliance			
Compliance		CSA C22.2 n° 14	
		IEC/EN/BS 60947-1	
		IEC/EN/BS 60947-5-1	
		UL508	
Certificates		cULus	
ETIM classification			
ETIM 8.0		EC002611 - Control switch	