


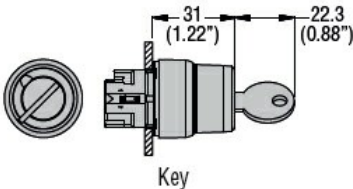

Product designation			Selector switch actuator key - 2 position		
Product type designation			LPSS34		
General characteristics					
Colour			Black		
Type of positions			0 < 1, key extraction in 0		
Material			Aluminium and zinc alloy		
IEC degree of protection			IP66, IP67 and IP69K		
Mechanical features					
Mechanical life			cycles	1000000	
Fixing			Without mounting adapter		
Mounting adapter			LPXAU120M		
UL technical data					
UL degree of protection			Type1, 2, 3R, 4, 4X, 12, 12K		
Ambient conditions					
Temperature			Operating temperature		
			min	°C	-25
			max	°C	+70
			Storage temperature		
			min	°C	-40
			max	°C	+85
Dimensions					
					
Certifications and compliance					
Compliance			CSA C22.2 n° 14		
			IEC/EN/BS 60947-1		
			IEC/EN/BS 60947-5-1		
			UL508		
Certificates			cULus		
ETIM classification					
ETIM 8.0			EC002611 - Control switch		