



Enclosures with
cut-outs for
Ø22mm units -
with hole for 1
actuator
LPZM

Product designation

Product type designation

General characteristics

Colour	Grey
IEC degree of protection	IP66 and IP67

Mechanical features

Weight	g	349
--------	---	-----


UL technical data

UL degree of protection	NEMA 4X
-------------------------	---------

Ambient conditions

Temperature			
Operating temperature	min	°C	-25
	max	°C	+70
Storage temperature	min	°C	-40
	max	°C	+85

Dimensions

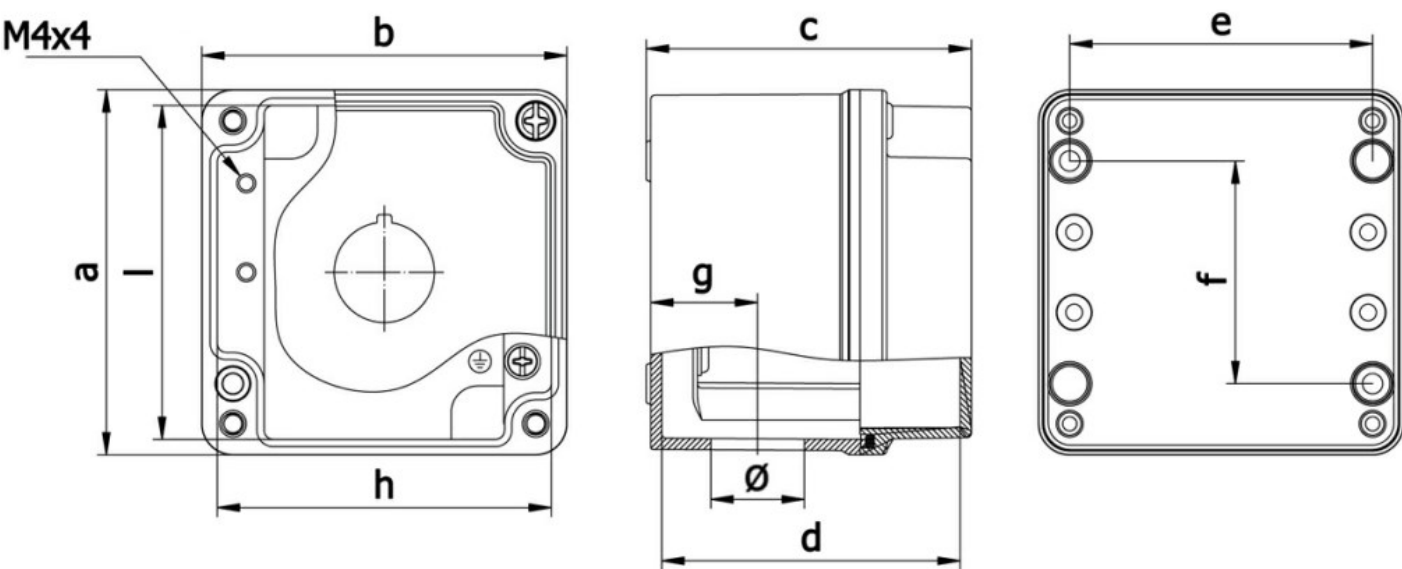

a	b	c	d	e	f	g	h	l	Ø
80	80	73	67	68	50	24	75	75	21

Certifications and compliance

Compliance

CSA C22.2 n° 14

IEC/EN 60947-1

IEC/EN 60947-5-1

UL508

Certificates

cULus

EAC

ETIM classification

ETIM 8.0

EC000200 -
Enclosure for
control circuit
devices