



Enclosures with cut-outs for Ø22mm units - with hole for 5 actuators
LPZM

Product designation

Product type designation

General characteristics

Colour	Grey
IEC degree of protection	IP66 and IP67

Mechanical features

Weight	g	680
--------	---	-----


UL technical data

UL degree of protection	NEMA 4X
-------------------------	---------

Ambient conditions

Temperature				
Operating temperature	min	°C	-25	
	max	°C	+70	
Storage temperature	min	°C	-40	
	max	°C	+85	

Dimensions

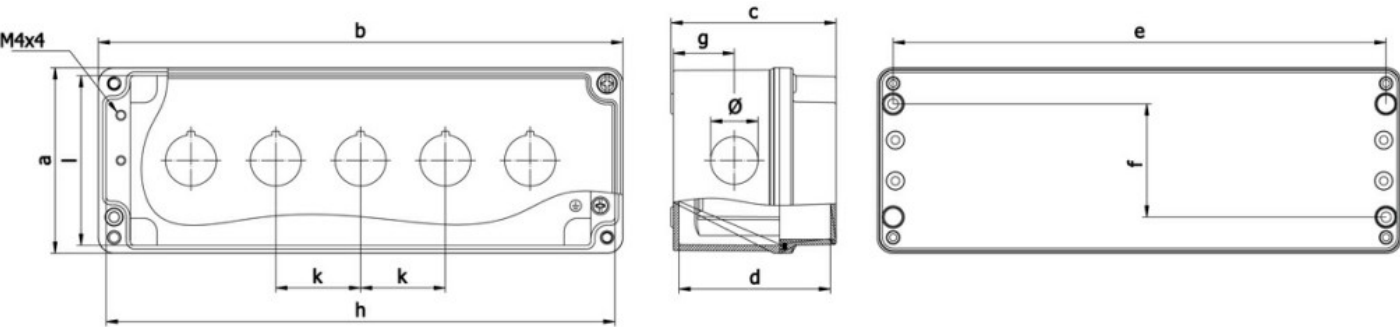

a	b	c	d	e	f	g	h	i	k	Ø
80	230	73	67	218	50	27	225	75	37.5	21

Certifications and compliance

Compliance	CSA C22.2 n° 14
	IEC/EN 60947-1
	IEC/EN 60947-5-1
	UL508

Certificates	cULus
	EAC

ETIM classification

ETIM 8.0

EC000200 -
Enclosure for
control circuit
devices