



Product designation

Plastic control
station without
actuators - for 4
actuators
LPZP4A8

Product type designation

General characteristics

Colour	Grey
Material	Polycarbonate
IEC degree of protection	IP66, IP67, IP69K

Mechanical features

Tightening torque for terminals max	Nm	1.8
Weight	g	200


UL technical data

UL degree of protection	1, 2, 3R, 4, 4X, 12K
-------------------------	-------------------------

Ambient conditions

Temperature			
Operating temperature			
	min	°C	-25
	max	°C	+70
Storage temperature			
	min	°C	-40
	max	°C	+85

Dimensions

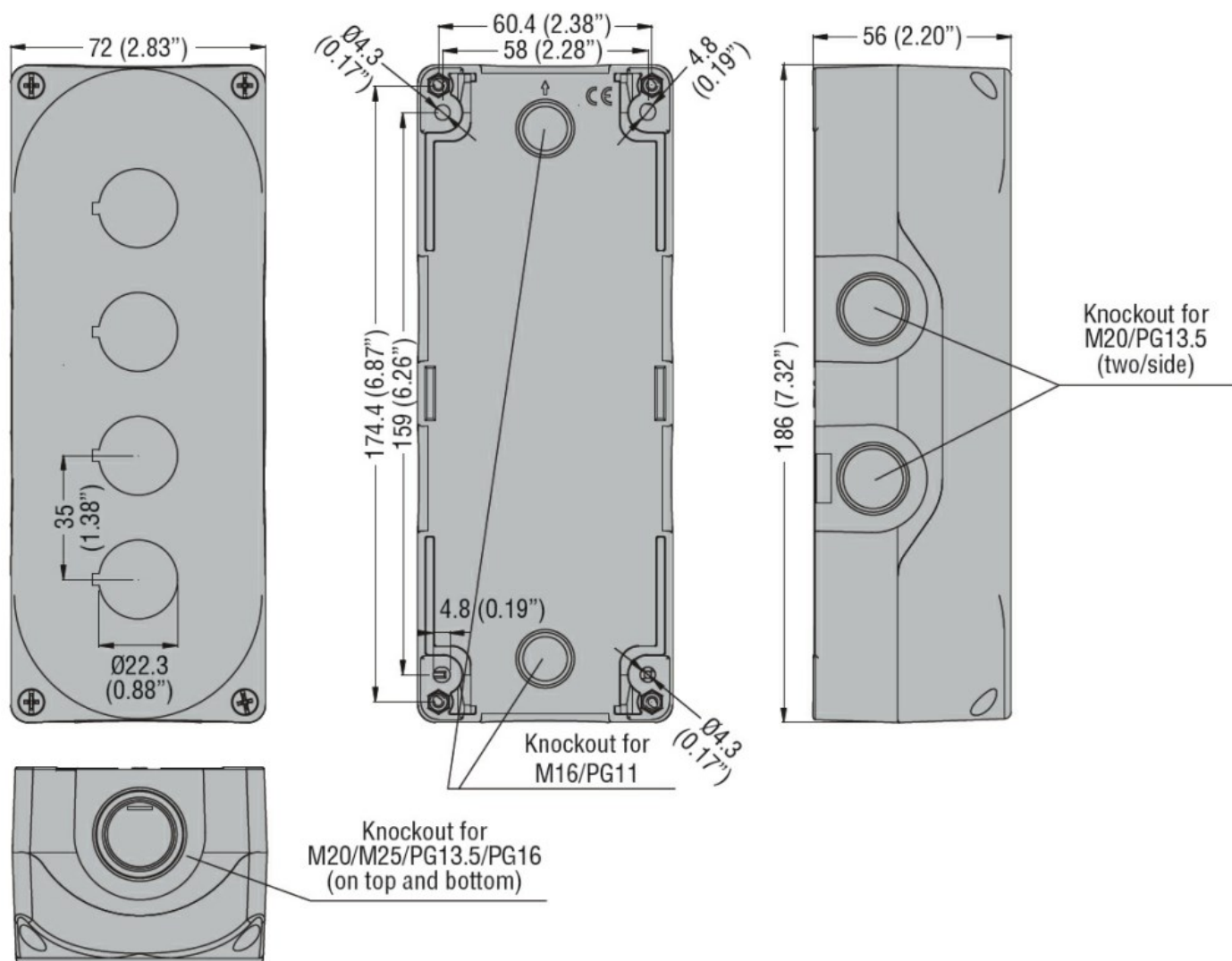

Certifications and compliance

Compliance

CSA C22.2 n° 14

IEC/EN 60947-1

IEC/EN 60947-5-1

UL508

Certificates

cULus

EAC

ETIM classification

ETIM 8.0

EC000200 -
Enclosure for
control circuit
devices