


# Motor Start Capacitors

MARS SERIES **119**



11908

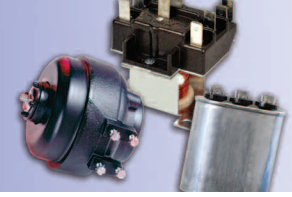

JARD Motor Start Capacitors provide a low cost alternative to popular models available. MARS offers the largest assortment of capacitor ratings in the industry.

These electrolytic capacitors feature a hermetically sealed black bakelite case which permanently protects the capacitor from oil, dirt, grease or moisture.

Capacitor accessories – see page J-7

## 110/125 Dual Voltage AC

JARD NO.	MICROFARAD	CASE SIZE
11902	21-25	1
11903	25-30	1
11904	30-36	1
11905	36-43	1
11906	43-56	1
11907	56-67	1
11908	72-88	1
11909	88-108	1
11910	108-130	1
11912	124-156	1
11911	130-156	1
11913	145-175	1
11914	161-193	1
11915	189-227	1
11916	200-240	1
11917	216-259	1
11918	233-292	1
11919	270-324	1
11920	300-360	1
11921	324-388	2
11922	340-408	2
11923	378-440	2
11924	400-480	4
11971	430-516	4
11925	460-552	4
11926	540-648	4
11927	590-708	4
11947	645-774	4
11928	708-850	4
11972	815-970	5
11929	829-995	5
11973	850-1020	5
11930	1000-1200	5
11974	1290-1548	5

## 165 Volts AC

JARD NO.	MICROFARAD	CASE SIZE
11975	72-88	1
11976	88-108	1
11977	108-130	1
11931	124-149	1
11932	145-175	1
11933	161-193	1
11934	189-227	1
11978	216-259	2
11935	233-292	2
11936	270-324	2
11979	340-408	4
11980	378-455	4
11994	400-480	4
11981	540-648	4
11982	710-850	5
11983	810-972	5

## 220/250 Dual Voltage AC

JARD NO.	MICROFARAD	CASE SIZE
11938	21-25	1
11939	25-30	1
11940	30-36	1
11941	36-43	1
11942	43-56	1
11943	56-72	1
11984	59-71	1
11937	64-77	1
11944	72-88	1
11945	88-108	2
11946	108-130	4
11948	124-156	4
11949	145-175	4
11950	161-193	5
11951	189-227	5
11952	216-259	5
11953	233-292	5
11954	270-324	5
11985	280-336	4
11986	320-384	4
11987	340-408	4
11988	378-455	5
11989	400-480	5
11990	430-516	5
11991	630-750	8

## 330 Volts AC

JARD NO.	MICROFARAD	CASE SIZE
11955	21-25	1
11956	25-30	1
11957	30-36	1
11958	36-43	1
11959	43-56	4
11995	56-72	2
11960	64-77	4
11961	72-88	4
11962	88-108	4
11963	108-130	4
11964	130-156	5
11965	124-156	5
11992	135-162	5
11966	145-175	5
11967	161-193	5
11968	189-227	5
11969	216-259	7
11970	270-324	7
11993	300-360	8

## CASE DIMENSIONS\*

CASE SIZE	DIAMETER IN INCHES	LENGTH INCHES
1	1.44	2.75
2	1.44	3.38
4	1.81	3.38
5	1.81	4.38
6	2.06	3.38
7	2.06	4.38
8	2.56	4.38

\*Capacitors may be put in different case sizes occasionally, but will not be larger than those stated.