


Unit Bearing Motors - Shaded Pole - GE

4 inch dia. MARS SERIES 010

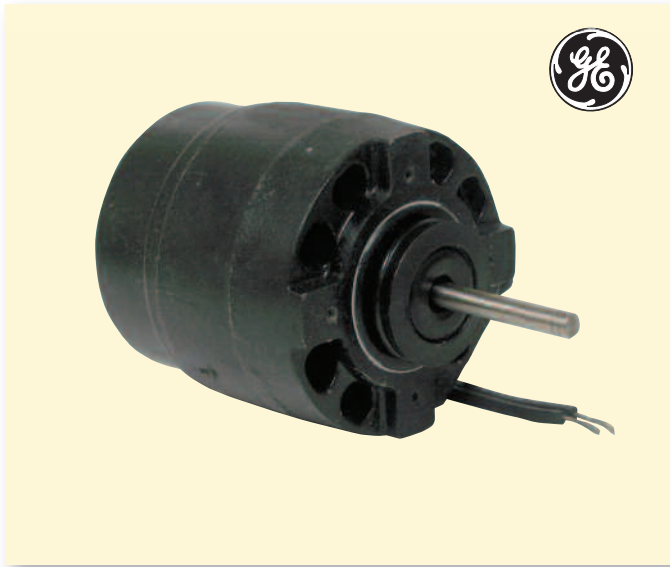

5KSP11 Unit Bearing Shaded Pole Motors


GE 5KSP11 shaded pole motors are suitable for use in a wide variety of fan duty applications. Proven all-angle unit bearing design for trouble free operation. Can be resilient base, strap, or end mounted.

Features:

- All angle unit sleeve bearings
- Resilient base, strap, or end mounting
- 5/16 inch shaft diameter ground lead
- 12 inch leads
- For mounting bases & accessories see page M-73 to M-75
- See the airMARS section of this catalog for fan blades & accessories

Specifications:

- Single phase, 60 Hertz
- Overload protection
- Fan duty, continuous, air over
- Shaft end has four 8-32 tapped holes

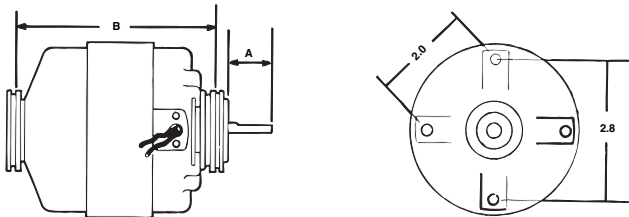

1550 rpm - 4 pole

MARS NO.	GE NO. 5KSM92	HP	VOLTS	AMPS	ROT OSE	ENCL	DIMENSIONS		BASE NO.
							A	B	
01431	KFL2005S	1/30	115	1.74	CW	OPEN	1.25	4.82/4.70	08042
01441	KFL2003S	1/30	115	1.74	CCW	OPEN	1.25	4.82/4.70	08042
01432	KFL2009S	1/30	208-230	.87	CW	OPEN	1.25	4.82/4.70	08042
01442	KFL1009S	1/30	208-230	.87	CCW	OPEN	1.25	4.82/4.70	08042
01331 ⁽¹⁾	KFL2011S	1/20	115	2.2	CW	OPEN	2.00	4.82/4.70	08042
01341 ⁽¹⁾	KFL2004S	1/20	115	2.2	CCW	OPEN	2.00	4.82/4.70	08042
01332 ⁽¹⁾	KFL2007S	1/20	208-230	1.1	CW	OPEN	2.00	4.82/4.70	08042
01342 ⁽¹⁾	KFL2012S	1/20	208-230	1.1	CCW	OPEN	2.00	4.82/4.70	08042
01232 ⁽²⁾⁽³⁾	KFL3006S	1/15	230	1.2	CW	OPEN	1.50	4.875	NONE

(1) 34 inch leads
 (2) 30 inch leads
 (3) 60/50 Hertz