

Midget Fuse Holder - 600 Volt

30 Amp Sectional Version


600 Volts

Specifications:

- Have Been Tested & Approved for 10,000 Amp Interrupting Capacity
- Base, White Nylon, 105° C Connector, Box Type, Accepts up to #10 AWG Wire, either Terminated or Non-Terminated
- Clip, Copper Alloy, Tin Plated
- UL Recognized File No. E35113
- CSA Certified File No. LR21455
- C E



Catalog#	Description	Std. Pack	Wire Range	Fuse Size	Fuses
6W30A1F	Flat Mount	10	#10-#14 AWG CU Stranded	13/32" DIA BY 1 1/2" LONG	A13X-2, A25Z-2, A60Q-2, A6Y-2B, AGN, ATM, ATQ, BAF, BAN, BLF, BLN, BLS, FLA, FLM, FLQ, FNM, FNQ, GFN, GGO, KLK, KLKD, KLQ, KTK, OTM, TRM
6W30A1C	Channel Mount				
6WE-F	End Piece-Flat				
6WE-C	End Piece-Channel				
MC	Channel Clamp	25			
MPC-6	6 Foot Channel	-			
MPC-3	3 Foot Channel				
GR-2	1/8" Diameter X 2" Long Nylon Rod				

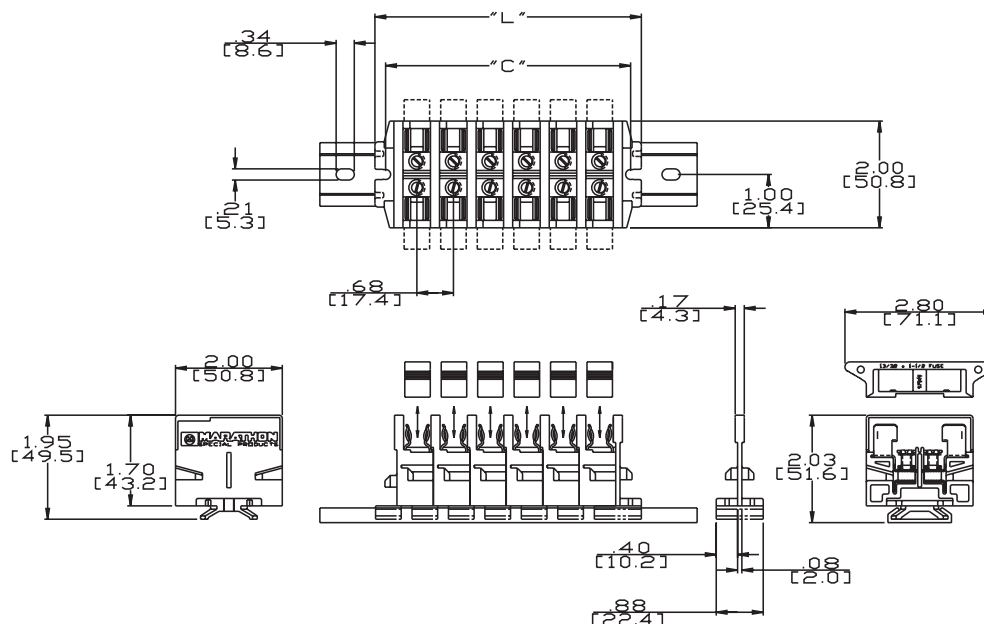

Flat Mount

$$L = 0.88 + (0.68 \times N)$$

$$C = 0.48 + (0.68 \times N)$$

N = No. of Poles

Channel Dimensions

$$LCH = L + 2.25$$