

STUDED FEED-THRU

ELECTRICAL:

Volts / amps - see table

Wire range is determined by the compression lugs used

Short circuit current rating (SCCR) of 10K

Factory and field wiring

STANDARDS:

UL 1059 recognized file no. XCFR2.E62806

CSA certified file no. LR19766 (CSA C22-2 No. 158)

CE (Component IEC 60947-7-1)

RoHS compliant (All)


WEBSITE RESOURCES:

Detailed product data sheets


- Material information
- Termination & mounting specifications
- Multiple wire rating specifications
- Detailed SCCR information

Dimensional drawings & 3D CAD files

Accessories available

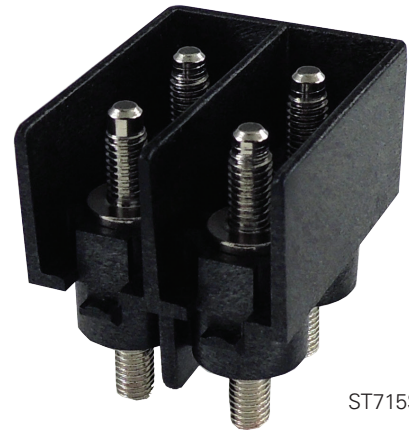

ST715S1902

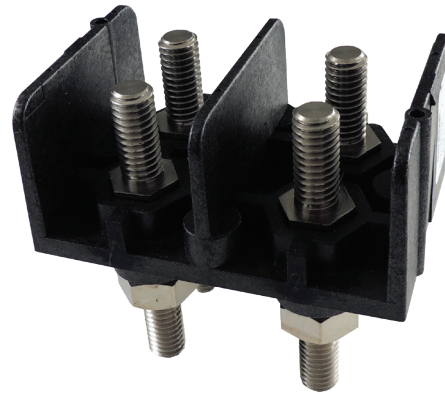

ST723B3802

ORDERING CODE:

VOLTS	AMPS	SERIES	POLES (xx)	HARDWARE OPTIONS
300	80	ST715S19xx	02	Blank – No hardware UH – All nuts shipped bulk AH – All nuts assembled DL – Assembled barrier side, remainder shipped bulk
600	380	ST723B38xx	01/02	Blank – No hardware UH – All nuts shipped bulk AH – All nuts assembled DL – Assembled barrier side, remainder shipped bulk