

# Product Data Sheet




## 37TB XX B

Replace "XX" 02 through 20 for number of poles

### Military Class Terminal Board

15 Amps

300 Volts

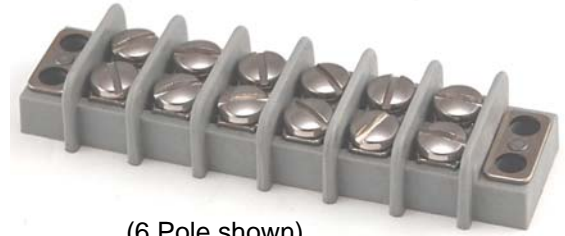

(6 Pole shown)

#### Copper Wire Only

Double Row  
3/8" Centers

Recommended Maximum size wire: #16 AWG

#### Electrical Ratings:

- 15 Amps
- 300 Volts

#### Mechanical Ratings:

- Maximum insulator base temperature: 130°C (266°F)\* UL RTI
- Flammability rating of insulator base: UL 94V-0

#### Materials:

- Insulator base: Valox 420 SEO (GPT-30F), Grey color
- Terminals: Brass, Nickel plated, Ultrasonically inserted
- Screws: Brass, Nickel plated, 6-32 Binder head, slotted
- End Plates: Brass, Nickel plated

#### Agency Compliances:

- A-A-59125 / 1 , (supercedes MIL-T-55164 / 1)
- GPT-30F in accordance with MIL-M-24519
- RoHS Compliant
- DFARS Compliant

#### Wire Range:

- Maximum size: #16 AWG Copper
- Recommended Torque: 6 – 8 in. lbs. (0.7 – 0.9 N·m)

Suggested product mounting hardware: #6 fastener, torque to 10-15 in. lbs.

