

GROUNDING LUG

GL20 - Part No. 9718102



Wire Range

- #2/0 - #14 AWG CU Wire
- #2/0 - #12 AWG AL Wire
- See tables below for Flexible stranded approvals

Electrical Ratings:

- 175A copper wire, 135A aluminum wire (Based on NEC code, 75°C wire)

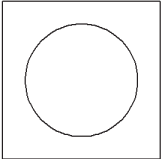
Agency Compliance

- UL Recognized Wire Connector - File ZMVV2.E43665
- Supplemental UL Certification: Grounding and Bonding Equipment (KDER)
- Final acceptance of this component is dependent upon its installation and use in complete equipment submitted to UL
- CSA Certified, CSA File No. 63510-25 (Wire Classes B & C only)
- RoHS Compliant

Material Information

- Connector: Aluminum, tin plated
- Terminal screws: Steel, nickel plated - painted green

Termination Specifications

Wire Opening	Wire Size (CU Stranded)	Torque	Wires / Terminal	Wire Class (UL) ¹
	2/0 - 6	5.6 N·m (120 lbf·in)	1	B, C
	8	4.5 N·m (40 lbf·in)	1	B, C, G, H, I (DLO)
	10 - 14	4 N·m (35 lbf·in)	1	B, C, G, H, I (DLO)

Drawing

