




# DS DIMENSIONS – Provided in inches

Dimensions are for reference only and may change depending on accessories used. For precise dimensions contact MELTRIC Engineering.

## Plug

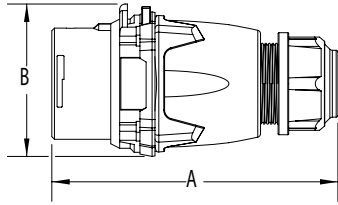


## Inlet

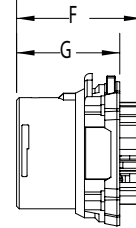
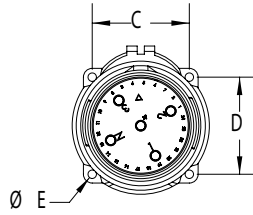


| PRODUCT          | A     | B    | C    | D    | ØE   | F    | G    |
|------------------|-------|------|------|------|------|------|------|
| DS20             | 5.72  | 2.79 | 1.89 | 1.89 | 0.2  | 2.28 | 1.86 |
| DS30             | 6.15  | 3.23 | 2.17 | 2.17 | 0.2  | 2.93 | 2.07 |
| DS60/DS100c/DS7c | 6.70  | 3.77 | 2.59 | 2.59 | 0.24 | 3.42 | 2.38 |
| DS100            | 8.33  | 4.59 | 3.20 | 3.2  | 0.24 | 4.14 | 3.04 |
| DS200            | 10.30 | 5.67 | 3.86 | 3.86 | 0.26 | 4.66 | 3.20 |


## Connector

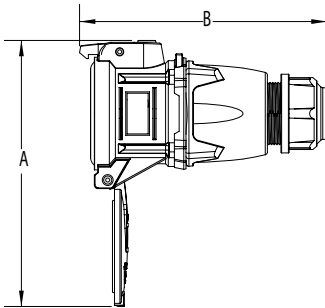

## Receptacle

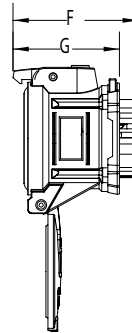
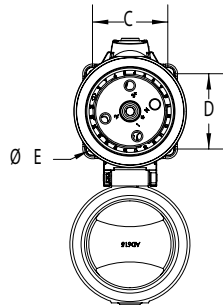


## Extended Draw bars

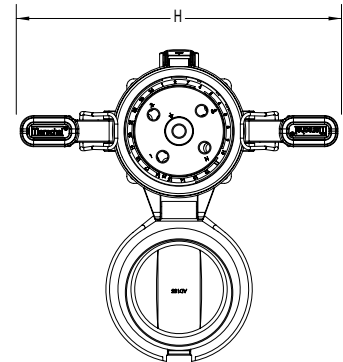


| PRODUCT          | A     | B     | C    | D    | ØE   | F    | G    | H     |
|------------------|-------|-------|------|------|------|------|------|-------|
| DS20             | 6.32  | 6.38  | 1.89 | 1.89 | 0.2  | 3.3  | 2.60 | N/A   |
| DS30             | 7.16  | 6.93  | 2.17 | 2.17 | 0.2  | 3.73 | 2.87 | N/A   |
| DS60/DS100c/DS7c | 8.46  | 7.75  | 2.59 | 2.59 | 0.22 | 4.53 | 3.37 | N/A   |
| DS100            | 11.04 | 10.02 | 3.20 | 3.2  | 0.23 | 5.71 | 4.74 | 11.25 |
| DS200            | 11.54 | 10.87 | 3.86 | 3.86 | 0.26 | 6.21 | 4.75 | 12.07 |

## Box/30° Angle/ Receptacle/Plug

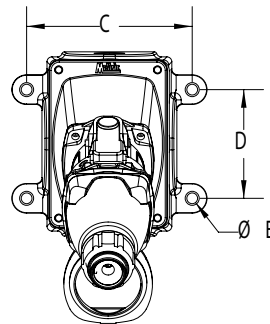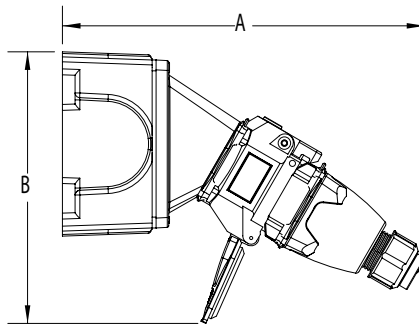


| PRODUCT          | A     | B     | C    | D    | ØE   |
|------------------|-------|-------|------|------|------|
| DS20             | 9.84  | 7.29  | 4.19 | 2.75 | 0.27 |
| DS30             | 10.30 | 8.39  | 4.19 | 2.75 | 0.27 |
| DS60/DS100c/DS7c | 11.87 | 10.45 | 5.00 | 3.81 | 0.33 |
| DS100            | 16.06 | 11.77 | 6.75 | 4.25 | 0.31 |
| DS200            | 15.76 | 11.54 | 8.13 | 6.38 | 0.31 |

### 30° Angle/Receptacle/Plug

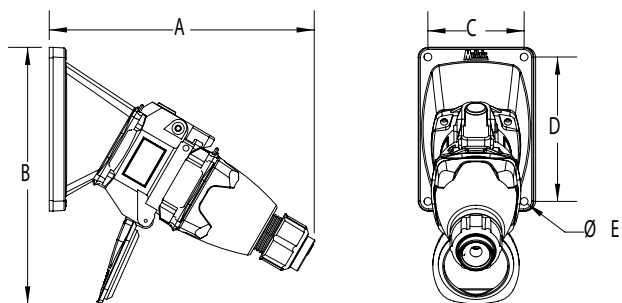

| PRODUCT          | A     | B     | C    | D    | ØE   |
|------------------|-------|-------|------|------|------|
| DS20             | 7.60  | 7.87  | 2.50 | 3.75 | 0.22 |
| DS30             | 8.19  | 8.44  | 2.50 | 3.75 | 0.22 |
| DS60/DS100c/DS7c | 9.17  | 10.16 | 3.43 | 4.83 | 0.26 |
| DS100            | 14.09 | 12.05 | 4.83 | 4.83 | 0.28 |
| DS200            | 11.61 | 15.03 | 6.50 | 6.50 | 0.25 |


### 70° Wall Box/Receptacle

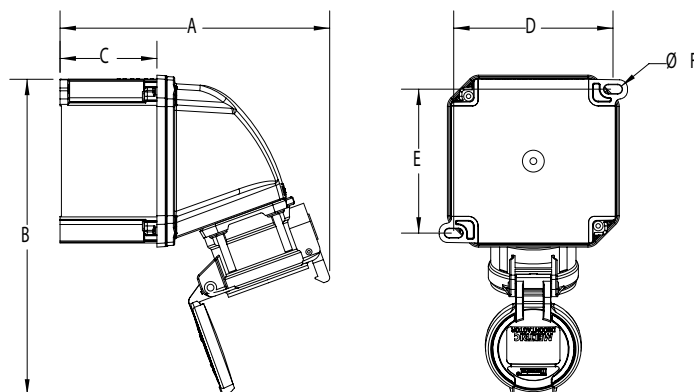

| PRODUCT           | A    | B     | C    | D    | E    | ØF   |
|-------------------|------|-------|------|------|------|------|
| DS20              | 7.78 | 9.11  | 2.80 | 4.60 | 4.15 | 0.26 |
| DS30*             | 8.91 | 11.55 | 2.80 | 6.17 | 5.73 | 0.26 |
| DS60/DS100c/DS7c* | 9.07 | 12.24 | 2.80 | 6.17 | 5.73 | 0.26 |

\* Box has 4 mounting feet

### Plug/Connector

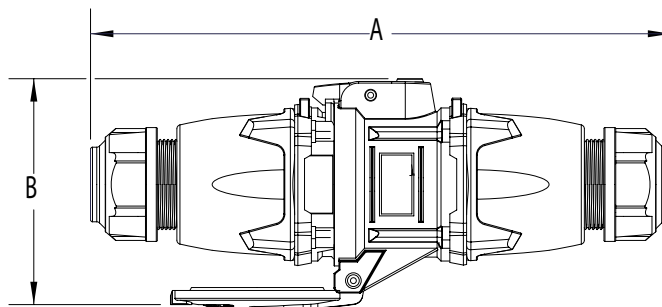

| PRODUCT          | A     | B    |
|------------------|-------|------|
| DS20             | 10.20 | 4.61 |
| DS30             | 10.91 | 5.71 |
| DS60/DS100c/DS7c | 12.17 | 6.57 |
| DS100            | 19.53 | 8.03 |
| DS200            | 23.15 | 8.00 |