



# Cable Entry System

## KADP Cable Entry System



KADP Cable Entry Plate | ILME Size 24 Panel Cutout | IP66 Rating



Part Number	# of Entries	Cable Diameter Range										
		1.5 ~ 2.6 mm	2.5 ~ 5.0 mm	3.0 ~ 5.5 mm	3.0 ~ 6.5 mm	4.1 ~ 8.1 mm	5.0 ~ 9.2 mm	8.0 ~ 12.0 mm	8.0 ~ 12.5 mm	9.0 ~ 14.0 mm	9.6 ~ 15.9 mm	14.0 ~ 20.0 mm
KADP-24-11	11				4		4					3
KADP-24-12	12							12				
KADP-24-13	13			2		6				4		1
KADP-24-14	14				6		4				4	
KADP-24-17	17						17					
KADP-24-17-1	17				11	1			5			
KADP-24-22	22				16		4		2			
KADP-24-23	23					23						
KADP-24-29	29				29							
KADP-24-BLI	0											

### Application



For introduction of cables, hoses, pneumatic and hydraulic lines

### Benefits

Fast and simple installation  
Up to 10 times faster than with cable glands  
Space savings of over 50%

### Mounting

Usable on panel cutouts Size 24 ILME industrial multipole connectors (e.g. Harting or Wieland), mounting in wall thicknesses from 1.5 to 2.0mm. For plates with thicknesses greater than 2.0 mm the cable entry plate KADP can be attached with screws.

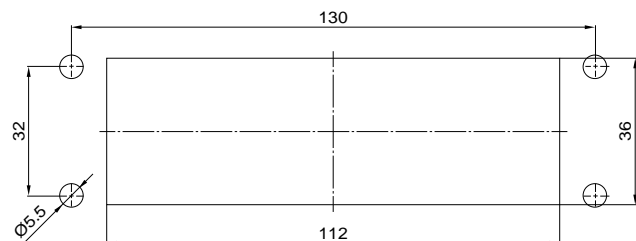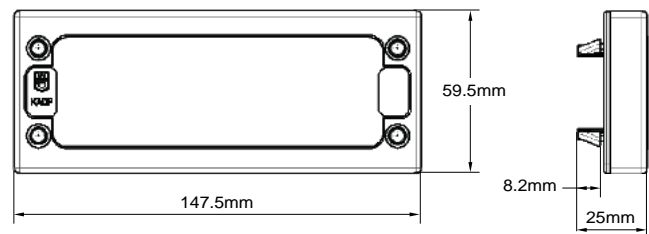

Hole Dimensions

### Specifications:

Flange: Polyamide PA6 V-0  
Elastomeric Plate: EPDM  
Sealing: TPE  
Temperature: -30°C to +100°C (-22°F to +212°F)