



Cable Glands Accessories

Metric, PG & NPT Threads Flat & Festoon Cable Glands



Flat & Festoon Cable Glands | Metric, PG & NPT Threads | IP66/IP65 Rating

Cable Glands for Flat Cable Applications


Mencom's plastic and brass cable glands are perfect for flat and festoon cables. Sealing ratings up to IP 66 can be obtained. A Locking Nut is supplied on all Metric and PG threaded parts. An O-Ring is not needed for the plastic style cable glands smaller than M32. O-Rings are supplied on M32 and larger sizes.

Plastic Version									
Part Number		A Wrench Flats (mm)	B Thread Length (mm)	S1 DIM MIN (mm)	S1 DIM MIN (mm)	S DIM MIN (mm)	S DIM MIN (mm)	Thread Type	Mounting Hole Clearance (mm)
Gray	Black								
PFG-M20-12X5	PFG-M20-12X5-B	24	8	12	8	5	2	M20 X 1.5	20.2
PFG-M25-16.3X6	PFG-M25-16.3X6-B	29	8	16.3	10	6	2	M25 X 1.5	25.2
PFG-M32-20X9	PFG-M32-20X9-B	36	10	20	12	9	3	M32 X 1.5	32.2
PFG-M40-27X10	PFG-M40-27X10-B	46	10	27	19	10	3	M40 X 1.5	40.2
PFG-M50-34X13	PFG-M50-34X13-B	55	12	34	23	13	4	M50 X 1.5	50.2
PFG-M63-45X15	PFG-M63-45X15-B	68	12	45	32	15	6	M63 X 1.5	63.2
PFG-1/2-12X5	PFG-1/2-12X5-B	22	13	12	8	5	2	1/2-14 NPT	21.2
PFG-13.5-12X5	PFG-13.5-12X5-B	22	6.5	12	8	5	2	PG13.5	20.2

Brass Version								
Part Number	A Wrench Flats (mm)	B Thread Length (mm)	S1 DIM MIN (mm)	S1 DIM MIN (mm)	S DIM MIN (mm)	S DIM MIN (mm)	Thread Type	Mounting Hole Clearance (mm)
MFG-M20-12X5	24	6	12	9	5	2	M20 X 1.5	20.2
MFG-M25-16.3X6	29	7	16.3	11	6	2	M25 X 1.5	25.2
MFG-M32-20X9	36	8	20	13	9	3	M32 X 1.5	32.2
MFG-M40-27X10	46	8	27	17	10	3	M40 X 1.5	40.2
MFG-M50-34X13	55	9	34	24	13	4	M50 X 1.5	50.2
MFG-M63-45X15	68	10	45	33	15	6	M63 X 1.5	63.2
MFG-1/2-12X5	22	13	12	9	5	2	1/2-14 NPT	21.2
MFG-13.5-12X5	22	6.5	12	9	5	2	PG13.5	20.2

Sealing for these cable glands is IP 66 only if the cable matches the slot dimensions exactly. For cables that are less than the "max", but more than the "min", the seals are rated to IP 54.

Longer thread lengths are available for some of these cable glands, please consult the factory.

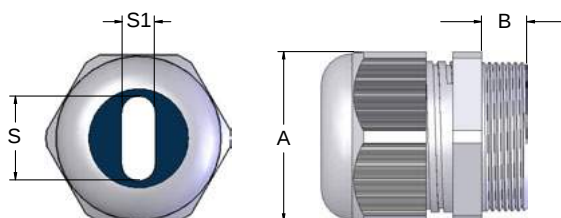

Plastic Version Materials:

Body: Polyamide
Seal: Neoprene

Brass Version Materials:

Body: Nickel Plated
Brass
Insert: Polyamide
Grommet : TPE
O-Ring : BUNA-N