




MCL (M16) Series Field Wireable Plugs


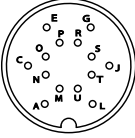
12 & 14 Conductor MCL Series Field Wireable Plugs, 24-28AWG




Field Wireable Plugs | Solder Cups | 60 Volt, 3 amps | IP67 Rating

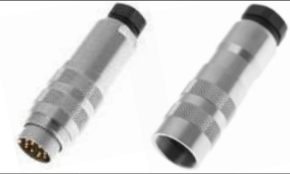


E
M16 Series

# of Poles	Male Faceview	Rating	Wire AWG	Cable O.D. Range	Part Number	
					Male Plug (Male Threads)	Female Plug (Female Threads)
12	 <p>M16 x 0.75</p>	60V 3A	24-28 AWG	4-6 mm	MCL-12MP-FW07	MCL-12FP-FW07
				6-8 mm	MCL-12MP-FW09	MCL-12FP-FW09
14	 <p>M16 x 0.75</p>	60V 3A	24-28 AWG	4-6 mm	MCL-14MP-FW07	MCL-14FP-FW07
				6-8 mm	MCL-14MP-FW09	MCL-14FP-FW09

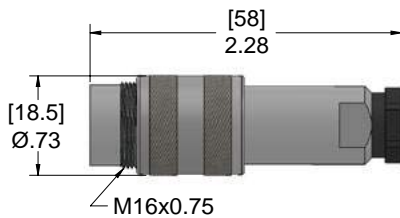

Male Plug with Male Threads

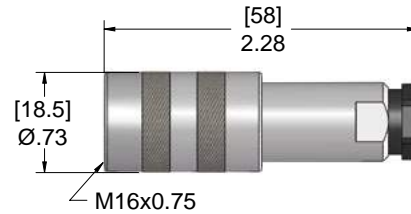

Female Plug with Female Threads

Specifications:

- Body: Nickel Plated Brass
- Contacts: Copper Alloy with Gold Plating
- O-Ring: NBR
- Insert: PBT
- Termination: Solder Cup 24-28 AWG
- Temperature: -30°C to +95°C (-22°F to +203°F)