



Euro-AC (M12) Series Field Wireable Plugs

4 & 5 Conductor MEC Series Field Wireable Plugs, 18-24AWG



Field Wireable Plugs | PG 7 & 9 Threads | 50 Volt, 4 amps | IP67 Rating




# of Poles	Male Faceview	Wire AWG Rating	Cable O.D. Range	Male plugs		Female Plugs	
				Straight	Right Angle	Straight	Right Angle
4	 M12 x 1	18-24 AWG 50V 4A	3-6.5 mm	MEC-4MP-FW07	MEC-4MP-FW07-R	MEC-4FP-FW07	MEC-4FP-FW07-R
		18-24 AWG 50V 4A	4-8 mm	MEC-4MP-FW09	MEC-4MP-FW09-R	MEC-4FP-FW09	MEC-4FP-FW09-R
5	 M12 x 1	18-24 AWG 50V 4A	3-6.5 mm	MEC-5MP-FW07	MEC-5MP-FW07-R	MEC-5FP-FW07	MEC-5FP-FW07-R
		18-24 AWG 50V 4A	4-8 mm	MEC-5MP-FW09	MEC-5MP-FW09-R	MEC-5FP-FW09	MEC-5FP-FW09-R

These connectors are easily wired by inserting the individual wires into the screw terminal contacts. The connectors are water tight to IP 67 and are fully mateable with other "EURO-AC" style connectors. Standard coupling nut is nickel plated brass, for stainless steel coupling nut add a "-SS" suffix. (e.g. MEC-4MP-FW07 becomes MEC-4MP-FW07-SS)

EURO-AC (M12) Series

Male Field Wireable Plugs

Female Field Wireable Plugs

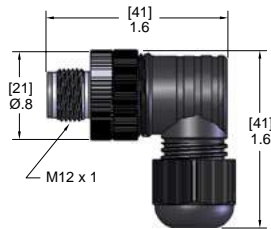

Male Straight

Male Right Angle

Female Straight

Female Right Angle

Specifications:

- Body: Black Polyamide
- Insulator: Black Polyamide
- Contacts: Copper Alloy with Gold Plating
- Coupling Nut: Nickel Plated Brass
- Seal: NBR
- Temperature: -25°C to +85°C (-13°F to +185°F)