





Ethernet (M12) Series Etherplug Field Wireable Plugs

4 & 8 Conductor Ethernet Series Field Wireable Plugs, 18-24/20-24AWG




Straight Field Wireable Plugs | Shielded | 4 Pole D-Coded | 8 Pole A-Coded | IP67 Rating

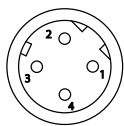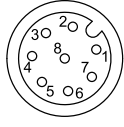

# of Poles	Male Faceview	Rating	Wire AWG	Cable O.D. Range	Part Number	
					Male Plugs	Female Plugs
4	 M12 x 1	250V 4A	18-24 AWG	3-9 mm	MDE45M-4MP-FW	MDE45M-4FP-FW
8	 M12 x 1	50V 4A	20-24AWG	6-8 mm	MDCM-8MP-FW	MDCM-8FP-FW

These connectors are easily wired by inserting the individual wires into the screw terminal contacts. The Connectors are water tight to IP 67 and are fully mateable with other D-Coded M12 connectors.

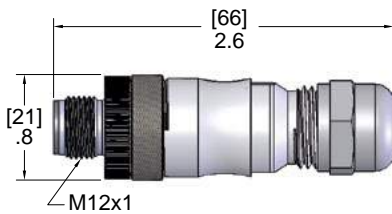

Male Straight



Female Straight



Specifications:

Body: Nickel Plated Brass
 Insulator: Black Polyamide
 Contacts: Copper Alloy with Gold Plating

Coupling Nut: Nickel Plated Brass
 Seal: NBR
 Temperature: -25°C to +85°C (-13°F to +185°F)

Ethernet Series

L