



Profibus-PA Series Field Wireable Plugs

4 Conductor Profibus-DP Series Field Wireable Plugs




Field Wireable Plugs | MIN & MDC | 600 Volt, 15 amps MAX | 250 Volt, 4 amps MAX | IP67 Rating




MIN Field Wireable Plugs						
# of Poles	Male Faceview	Rating	Wire AWG	Cable O.D. Range	Part Number	
					Male Plugs	Female Plugs
4		600V 15A MAX	14-22 AWG	5-13 mm	PBIN-4MPM-FW-SS	PBIN-4FP-FW-SS
				8-17 mm	PBIN-4MPM-FWX-SS	PBIN-4FP-FWX-SS

Connection via screw terminal. Voltage and amperage ratings are cable dependent and are based on 600V 14 AWG cable. Cables with lower voltage ratings and smaller conductors will lower these ratings.

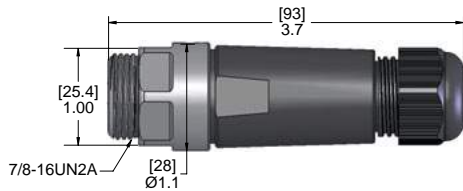

Male Straight with Male Threads

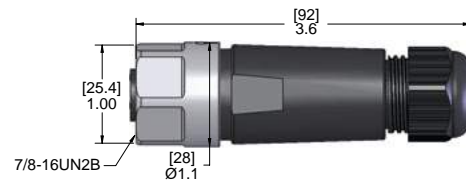

Female Straight with Female Threads

MDC Field Wireable Plugs						
# of Poles	Male Faceview	Rating	Wire AWG	Cable O.D. Range	Part Number	
					Male Plugs	Female Plugs
4		250V 4A MAX	18-24 AWG	3-6.5 mm	PBDC-4MP-FW07-SS	PBDC-4FP-FW07-SS
				4-8 mm	PBDC-4MP-FW09-SS	PBDC-4FP-FW09-SS
				8-10 mm	PBDC-4MP-FW11-SS	PBDC-4FP-FW11-SS

Connection via screw terminal. Voltage and amperage ratings are cable dependent and are based on 600V 14 AWG cable. Cables with lower voltage ratings and smaller conductors will lower these ratings.



Male Straight with Male Threads



Female Straight with Female Threads

Specifications:

Body: Polyamide
 Contacts: Copper Alloy with Gold Plating
 Coupling Nut: Stainless Steel
 O-Ring: NBR

Insert: PVC
 Connections: Screw Terminals
 Temperature: -40°C to +90°C (-40°F to +194°F)