

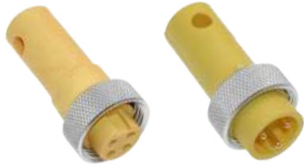


7/8" MIN Series Size I Accessories

MIN Series Size I Dummy Plugs

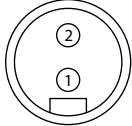
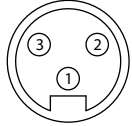
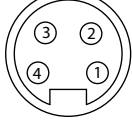
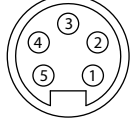
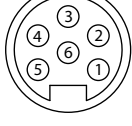


Dummy Plugs | Jumpered Pins | IP67 Rating



A

MIN Series Size I Cordsets

# of Poles	Male Faceview	Jumpers	Male Plugs	Female Plugs
2	 7/8"-16UN2	1 to 2	MIN-2MP-DP1	MIN-2FP-DP1
3	 7/8"-16UN2	2 to 3	MIN-3MP-DP1	MIN-3FP-DP1
4	 7/8"-16UN2	1 to 2 3 to 4	MIN-4MP-DP1	MIN-4FP-DP1
5	 7/8"-16UN2	2 to 4	MIN-5MP-DP1	MIN-5FP-DP1
6	 7/8"-16UN2	1 to 2 4 to 5	MIN-6MP-DP1	MIN-6FP-DP1

For stainless steel locking ring, add a "-SS" suffix. (e.g. MIN-3FP-DP1 becomes MIN-3FP-DP1-SS)

Alternate wiring is available, please consult the factory.

Terminating plugs are available in DeviceNet and Foundation Fieldbus, please see the DeviceNet (**Page K-8**) and Foundation Fieldbus (**Page M-8**) sections.

Specifications:

- Body: Oil Resistant Yellow PVC
- Contacts: Copper Alloy with Gold Plating
- Coupling Nut: Nickel Plated Brass
- Jumpers: 18 AWG
- Temperature: -40°C to +105°C (-40°F to +221°F)

