



MIL-SPEC Series Cordsets

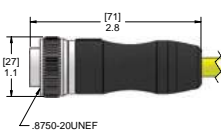
 
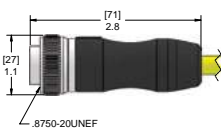
 
 
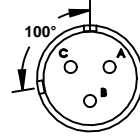

 
2, 3 & 4 Conductor 5015 Industrial Equiv. Cordsets, 16AWG



Straight Male Cordsets | Size 14S | 600 Volt, 13/10 amps | IP67 Rating



F
MIL-SPEC

Connector Body Style	Part Number	Cables	Features	Color Code	Faceview
	MS14S-2MP-**	Yellow PVC STOOW 2 X 16 AWG 600V, 13A -40°C to +150°C 9.5mm OD	Industry Standard PVC	North American A. White B. Black	 14S-2 0.8750"-20UNEF
	MS14S-3AMP-** MS14S-3BMP-** MS14S-3CMP-** (Yellow)	PVC STOOW 3 X 16 AWG 600V, 13A -40°C to 105°C 10mm OD	Industry Standard PVC	North American A. Green/Yellow B. Black C. White	 14S-3A 0.8750"-20UNEF
	MS14SP-3AMP-** MS14SP-3BMP-** MS14SP-3CMP-**	Yellow PUR AWM 3 X 16 AWG 600V, 13A -40°C to 80°C 10mm OD	Oil and Cutting Fluid Resistant Cut Resistant PUR		 14S-3B 0.8750"-20UNEF
	MS14SW-3AMP-** MS14SW-3BMP-** MS14SW-3CMP-** (YELLOW)	TPE SEOOW 3 X 16 AWG 600V, 13A -40°C to 80°C 10mm OD	Weld Slag Resistant TPE	North American A. Green/Yellow B. Black C. White	 14S-3C 0.8750"-20UNEF
	MS14S-4MP-** (YELLOW)	PVC STOOW 4 X 16 AWG 600V, 10A -40°C to 105°C 10.8mm OD	Industry Standard PVC	North American A. Black B. White C. Red D. Green/Yellow	 14S-4 0.8750"-20UNEF
	MS14SM-4MP-**	Yellow PVC STOOW With Foil Shield 4 X 16 AWG 600V, 10A -40°C to 80°C 10.8mm OD	Industry Standard PVC Foil Shield		
	MS14SW-4MP-**	Yellow TPE SEOOW 4 X 16 AWG 600V, 10A -40°C to 80°C 10.8mm OD	Weld Slag Resistant TPE		

** Lengths in meters. Standard Cable lengths are 1, 2, 4, 5, 6, 10 & 15 meters. Consult factory for other lengths.

Standard coupling nut is nickel plated aluminum, for black anodized aluminum coupling nut add a "-BA" suffix. (e.g. MS14S-3MP-1M becomes MS14S-3MP-1M-BA)

Insert clocking, where available, is indicated by placing 'A, B or C' after the pin count in the part number. (e.g. MS14S-3MP-** becomes MS14S-3AMP-**)