




1 1/8" MIN Series Size III Cordsets

19 Conductor MIN Series Size III Cordsets, 18/22AWG



Double Ended Cordsets | 300 Volt, 4 & 2 amps | 300 Volt, 8 & 3 amps | IP67 Rating

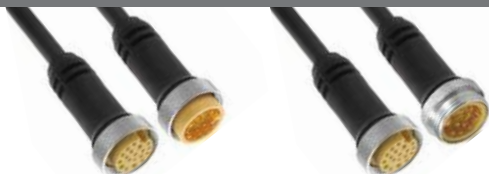

| Male Faceview | Part Number | Cables | Features | Color Code | Female Faceview |
|---------------------|---------------|--|---|--|---------------------|
| <p>1 1/8"-16UN2</p> | MINP-19MFP-** | Black PUR AWM With Foil Shield 3 x 18 AWG 300V, 4A 16 x 22 AWG 300V, 2A -40°C to +80°C 11mm OD | Oil and Cutting Fluid Resistant Cut Resistant PUR Foil Shield | North American 1. Violet 2. Red 3. Gray 4. Red/Blue 5. Blue*** 6. Green 7. Brown*** 8. White/Green 9. White/Yellow 10. White/Gray 11. Black 12. Green/Yellow*** 13. Yellow/Brown 14. Brown/Green 15. White 16. Yellow 17. Pink 18. Gray/Brown 19. Gray/Pink | <p>1 1/8"-16UN2</p> |

C
MIN Series Size III Cordsets


** Lengths in meters. Standard cable lengths are 1, 2, 4, 5, 6, 10 & 15 meters. Consult factory for other lengths.

*** Blue, Brown and Green/Yellow are 18 AWG wires.

Standard coupling nut is anodized aluminum, for stainless steel coupling nut add a "-SS" suffix. (e.g. MINP-19MFP-1M becomes MINP-19MFP-1M-SS)

For male threaded coupling nut replace "MFP" with "MFPM". (e.g. MIN-19MFP-1M becomes MIN-19MFPM-1M)

For available options for extension cables with right angle male and/or female ends, please consult the factory.

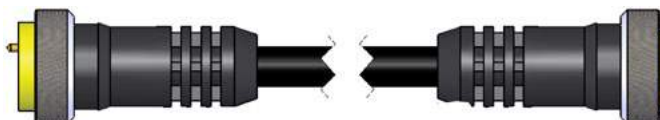

19 Pole Male - Female Extension