



1" MIN Power Series Cordsets

7 Conductor MIN Power Series Cordsets, 14/18AWG



Front Mount Receptacles | 1/2"-14 NPT Threads | Metric Threads | IP67 Rating



D
MIN Power Receptacles


# of Poles	Male Faceview	Color Code	Wire AWG Rating	Mounting Threads	Male Receptacles	Female Receptacles
7	<p>1"-16UN2</p>	North American 1. White/Black 2. Black*** 3. White*** 4. Red 5. Orange 6. Blue 7. Green/Yellow	2x14 AWG 5x18 AWG 300V 5A	1/2" NPT	MINH-7MR-**	MINH-7FR-**
				M20 x 1.5	MINH-7MR-**-M20	N/A

** Length in meters. 0.3m leads are standard. Longer lead lengths are available, please consult the factory for part numbers.


*** Black and White wires are 14 AWG.

For 1/2" receptacles with lengths of 15" or longer O-ring and lock nut are included.

1/2"-14 NPT Threads

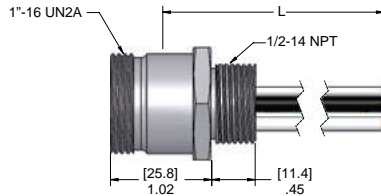

M20 Threads

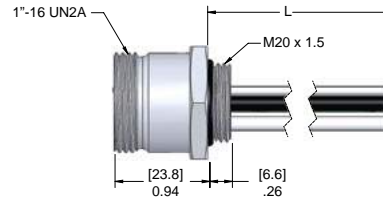

Specifications:

- Shell: Clear Anodized Aluminum
- Insulator: 105°C, Oil Resistant Yellow PVC
- Wire: 14 AWG: UL Style 1015, 600V
18 AWG: UL Style 1007, 300V
- Contacts: Copper Alloy with Gold Plating
- O-Ring: NBR
- Temperature: -40°C to 105°C (-40°F to +221°F)