






1 3/8" MIN Power Series Cordsets

4 & 5 Conductor MIN Power Series Cordsets, 10, 12 & 14AWG



Double Ended Cordsets | 600 Volt | IP67 Rating

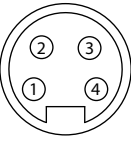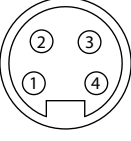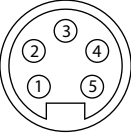

Male Faceview	Cables	Straight Male to Straight Female	Right Angle Male to Right Angle Female	Right Angle Male to Straight Female	Straight Male to Right Angle Female
 1.375"-16UN2	Gray PVC STOOW 4 X 10 AWG 600V, 25A -40°C to +105°C 18mm OD	PMIN-40MFP-**	PMIN-40MFP-**-R	PMIN-40MRFP-**	PMIN-40MFRP-**
	Gray PVC STOOW 4 X 14 AWG 600V, 15A -40°C to +105°C 14.7mm OD	PMIN-44MFP-**	PMIN-44MFP-**-R	PMIN-44MRFP-**	PMIN-44MFRP-**
 1.375"-16UN2	Black TPE TC-ER 4 X 10 AWG 600V, 25A -40°C to +90°C 13.2 mm OD	PMINW-40MFP-**-C011	PMINW-40MFP-**-R-C011	PMINW-40MRFP-**-C011	PMINW-40MFRP-**-C011
	Black TPE TC-ER 4 X 12 AWG 600V, 20A -40°C to +90°C 10.9mm OD	PMINW-42MFP-**-C011	PMINW-42MFP-**-R-C011	PMINW-42MRFP-**-C011	PMINW-42MFRP-**-C011
	Black TPE TC-ER 4 X 14 AWG 600V, 15A -40°C to +90°C 9.7mm OD	PMINW-44MFP-**-C011	PMINW-44MFP-**-R-C011	PMINW-44MRFP-**-C011	PMINW-44MFRP-**-C011
 1.375"-16UN2	Black TPE TC-ER With Braided Shield 4 X 10 AWG 1 x 14 AWG (Drain) 600V, 25A -40°C to +90°C 13.1 mm OD	PMINWB-450MFP-**-C011	PMINWB-450MFP-**-R-C011	PMINWB-450MRFP-**-C011	PMINWB-450MFRP-**-C011

D
PMIN Cordsets

** Lengths in meters. Standard cable lengths are 1, 2, 5, 10 & 15 meters. Consult the factory for other lengths.

Standard coupling nut is nickel plated brass, for stainless steel coupling add -SS suffix. (e.g. PMIN-40MFP-1M becomes PMIN-40MFP-1M-SS)

Straight

Right Angle



Male Plug

Female Plug

Male Plug

Female Plug