



MIN Power Series Extension Cables

3, 4 & 7 Conductor MIN Power Series Extension Cables, 14/18AWG



Double Ended Cordsets | 600V, 18A | 600V, 15A | 600V, 10 & 5A | IP67 Rating



D

MIN Power Cordsets

 
Male Faceview	Part Number	Cables	Features	Color Code	Female Faceview
<p>7/8"-16UN2</p>	MINH-3MFP-**	7/8" Size I Gray PVC STOOW 3 X 14 AWG 600V, 18A -40°C to +105°C 13.7mm OD	Industry Standard PVC	North American 1. Green/Yellow 2. Black 3. White	<p>7/8"-16UN2</p>
<p>7/8"-16UN2</p>	MINH-4MFP-**	7/8" Size I Gray PVC STOOW 4 X 14 AWG 600V, 15A -40°C to +105°C 14.9mm OD	Industry Standard PVC	North American 1. Black 2. White 3. Red 4. Green/Yellow	<p>7/8"-16UN2</p>
<p>1"-16UN2</p>	MINH-7MFPX-**	1" Size II Yellow PVC AWM 2 X 14 AWG 600V, 10A 5 X 18 AWG 600V, 5A -40°C to +105°C 12.1mm OD	Industry Standard PVC	North American 1. White/Black 2. Black*** 3. White*** 4. Red 5. Orange 6. Blue 7. Green/Yellow	<p>1"-16UN2</p>

** Lengths in meters. Standard cable lengths are 1, 2, 5, 10 & 15 meters. Consult the factory for other lengths.

*** Black and White wires are 14 AWG.


Standard coupling nuts are nickel plated brass for 3 & 4 pin and anodized aluminum for 7 pin, for stainless coupling nut add a "-SS" suffix. (e.g. MINH-4MFP-3 becomes MINH-4MFP-3-SS)

For extension cables with right angle female ends, please consult the factory.



3 & 4 Conductors

Male (Male Threads) - Female (Female Threads)

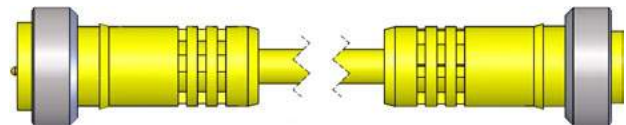

7 Conductors

Male (Female Threads) - Female (Female Threads)