



MCV (M23) Series Cordsets

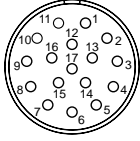
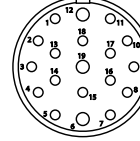
17 Conductor M23 Series Cordsets, 18AWG



Double Ended Cordsets | 150 Volt, 5 amps | IP67 Rating



E
M23 Series

Male Faceview	Part Number	Figure	Cables	Features	Color Code	Female Faceview
 <p>M23 x 1</p>	MCV-17MFPX-**-C010	A to D	Black PVC AWM 17 X 18 AWG 150V, 5A -40°C to +90°C 12.1mm OD	PVC ITC-ER/PLTC-ER	1. White 10. Violet 2. Brown 11. Gray/Pink 3. Green 12. Red/Blue 4. Yellow 13. White/Green 5. Gray 14. Brown/Green 6. Pink 15. White/Yellow 7. Blue 16. Yellow/Brown 8. Red 17. White/Gray 9. Black	 <p>M23 x 1</p>
	MCV-17MMFPX-**-C010	C to D				
	MCV-17MFRPX-**-C010	A to E				
	MCV-17MRFPX-**-C010	B to D				
	MCV-17MFPX-**-R-C010	B to E				

** Lengths in meters. Standard cable lengths are 1, 2, 4, 5, 6, 10 & 15 meters. Consult factory for other lengths.
 Standard coupling nut is nickel plated brass. Stainless steel coupling nut is available only for female threads.
 For stainless steel coupling nut add a "SS" suffix. (e.g. MCV-17MFPX-1M-C010 becomes MCV-17MFPX-1M-C010SS)

Figure A



Male (Female Threads) Plug

Figure B



Male (Female Threads) Plug

Figure C



Male (Male Threads) Plug

Figure D



Female (Female Threads) Plug

Figure E



Female (Female Threads) Plug