



MCVH (M23) Series Receptacles

6 & 8 Conductor M23 Series Receptacles



Panel Mount Receptacles | Crimp Pins | IP67 Rating



# of Poles	Male Faceview	Male Receptacles		Female Receptacles	
		Straight	Right Angle	Straight	Right Angle
6	 M23 x 1	MCVH-6MR-PM-CC	MCVH-6MR-PM-RT-CC	MCVH-6FR-PM-CC	MCVH-6FR-PM-RT-CC
8	 M23 x 1	MCVH-8MR-PM-CC	MCVH-8MR-PM-RT-CC	MCVH-8FR-PM-CC	MCVH-8FR-PM-RT-CC

E

M23 Series

Straight

Rotatable Right Angle

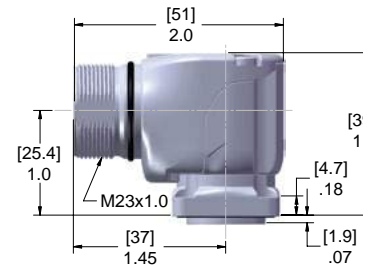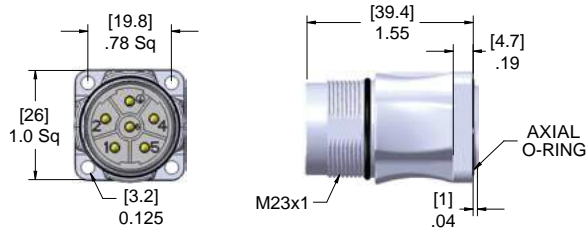

Specifications:

Body: PM-CC: Nickel Plated Brass
 RT-CC: Nickel Plated Zinc
 Insulator: Polyamide
 Contacts: Copper Alloy with Gold Plating
 O-Ring: FPM
 Temperature: -40°C to +105°C (-40°F to +221°F)

# of Poles	Crimp Pin	Wire AWG	Male Contacts	Female Contacts	
6&8* *Pins 1-4 for the 8 Pole	 Female Contact	 Male Contact	12 AWG	MCVH-MR-PIN-12	MCVH-FR-PIN-12
			14-16 AWG	MCVH-MR-PIN-16	MCVH-FR-PIN-16
			20-24 AWG	MCVH-MR-PIN-20	MCVH-FR-PIN-20
8 Pins A-D	 Female Contact	 Male Contact	18-22 AWG	MCVH-8MR-PIN-18	MCVH-8FR-PIN-18
			24-26 AWG	MCVH-8MR-PIN-24	MCVH-8FR-PIN-24

# of Poles	Crimp Tool	Crimp Tool Locator
6&7	CCPZ-MIL	MCTP-VH6-8

Crimp Tool and Crimp Tool Locator are ordered separately. Locators fit into crimp tool and are necessary for proper crimping.