









MAC (1/2"-20) Series Cordsets

4, 5 & 6 Conductor MAC Series Cordsets, 18/22AWG



Double Ended Cordsets | 300 Volt, 4 amps | IP67 Rating

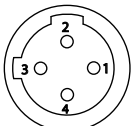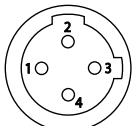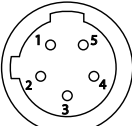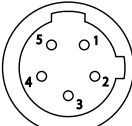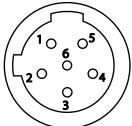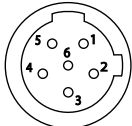

Male Faceview	Part Number	Cables	Features	Color Code	Female Faceview
 1/2"-20	MAC-4MFPX-**	Yellow PVC AWM 4 X 18 AWG 300V, 4A -40°C to +105°C 7.4mm OD	Industry Standard PVC	1. Red/Black 2. Red/White 3. Red 4. Green/Yellow	 1/2"-20
	MAC-4MFP-**	Yellow PVC AWM 4 X 22 AWG 300V, 4A -40°C to +105°C 5mm OD	Industry Standard PVC		
	MACB-4MFP-**	Yellow PVC AWM With Braided Shield 4 X 22 AWG 300V, 4A -40°C to +105°C 5.6mm OD	Industry Standard PVC Braided Shield		
 1/2"-20	MAC-5MFP-**	Yellow PVC AWM 5 X 22 AWG 300V, 4A -40°C to +105°C 5.8mm OD	Industry Standard PVC	1. Red/White 2. Red 3. Green/Yellow 4. Red/Yellow 5. Red/Black	 1/2"-20
	MACB-5MFP-**	Yellow PVC AWM With Braided Shield 5 X 22 AWG 300V, 4A -40°C to +105°C 6.3mm OD	Industry Standard PVC Braided Shield		
	MACP-5MFP-**-B	Black PUR AWM 5 X 22 AWG 300V, 4A -40°C to +80°C 5.8mm OD	Oil and Cutting Fluid Resistant Cut Resistant PUR		
 1/2"-20	MAC-6MFP-**	Yellow PVC AWM 6 X 22 AWG 600V, 4A -40°C to +105°C 5.8mm OD	Industry Standard PVC	1. Red/White 2. Red 3. Green/Yellow 4. Red/Yellow 5. Red/Black 6. Red/Blue	 1/2"-20
	MACB-6MFP-**	Yellow PVC AWM With Braided Shield 6 X 22 AWG 300V, 4A -40°C to +105°C 6.3mm OD	Industry Standard PVC Braided Shield		

G

Micro-AC Series (1/2"-20) Cordsets

** Lengths in meters. Standard cable lengths are 1, 2, 4, 5, 6, 10 & 15 meters. Consult factory for other lengths.

For extension cables with right angle male and/or female ends, please consult the factory.

Standard coupling nut is Nickel Plated Brass, for stainless steel coupling nut add a "SS" suffix. (e.g. MAC-5MFP-1M becomes MAC-5MFP-1M-SS)