



MAC (1/2"-20) Series Receptacles

2, 3, 4, 5 & 6 Conductor MAC Series Receptacles



Solder Cup Receptacles | 1/2"-14 NPT & M20 Threads | 300 Volt, 4 amps | IP67 Rating




G

Micro-AC Series (1/2"-20) Receptacles

# of Poles	Male Faceview	Rating	Wire AWG	1/2"-14 NPT		M20	
				Male Receptacle	Female Receptacles	Male Receptacle	Female Receptacles
2	 1/2"-20	300V 4A Max	18 AWG Max	MAC-2MR-2-SC	MAC-2FR-2-SC	MAC-2MR-M20-SC	MAC-2FR-M20-SC
3	 1/2"-20	300V 4A Max	18 AWG Max	MAC-3MR-2-SC	MAC-3FR-2-SC	MAC-3MR-M20-SC	MAC-3FR-M20-SC
4	 1/2"-20	300V 4A Max	18 AWG Max	MAC-4MR-2-SC	MAC-4FR-2-SC	MAC-4MR-M20-SC	MAC-4FR-M20-SC
5	 1/2"-20	300V 4A Max	18 AWG Max	MAC-5MR-2-SC	MAC-5FR-2-SC	MAC-5MR-M20-SC	MAC-5FR-M20-SC
6	 1/2"-20	300V 4A Max	18 AWG Max	MAC-6MR-2-SC	MAC-6FR-2-SC	MAC-6MR-M20-SC	MAC-6FR-M20-SC

Other mounting threads are available, please consult the factory for part numbers.


Male Receptacles

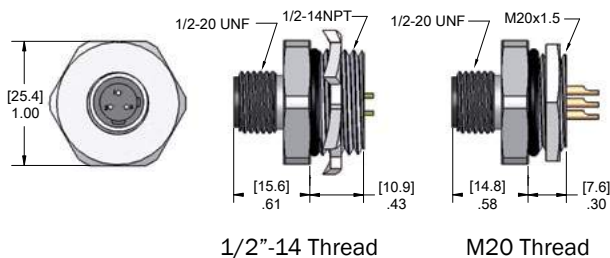

1/2"-14 Thread

M20 Thread

Female Receptacles

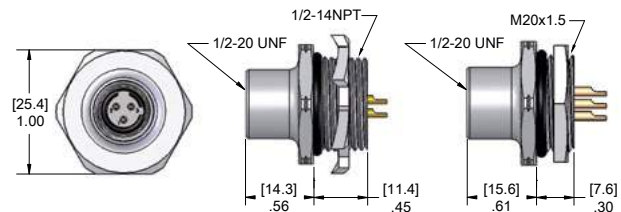

1/2"-14 Thread

M20 Thread

Specifications:

Shell: Clear Anodized Aluminum
Insulator: Polyamide
Contacts: Copper Alloy with Gold Plating
O-Ring: NBR

Lock Nut: Zinc PLated Steel
Jam Nut: Nickel Plated Brass
Temperature: -40°C to 105°C (-40°F to +221°F)