



MDC (M12) to MIN (7/8"-16UN) Cordsets

3, 4 & 5 Conductor MDC Series Cordsets, 18AWG



Double Ended Cordsets | Male MDC to Female MIN | 300 Volt, 4 amps | IP67 Rating




H

Micro-DC (M12) Series Cordsets

Male Faceview	Part Number	Cables	Features	Color Code	Female Faceview
<p>M12 x 1</p>	MDCIN-3MFPX-**	Yellow PVC AWM 3 X 18 AWG 300V, 4A -40°C to +105°C 7.4mm OD	Industry Standard PVC	1. Brown 2. Not Used 3. Blue 4. Black 5. Not Used	<p>7/8"-16UN2</p>
<p>M12 x 1</p>	MDCIN-4MFPX-**	Yellow PVC AWM 4 X 18 AWG 300V, 4A -40°C to +105°C 7.4mm OD	Industry Standard PVC	1. Brown 2. White 3. Blue 4. Black	<p>7/8"-16UN2</p>
<p>M12 x 1</p>	MDCIN-5MFPX-**	Yellow PVC AWM 5 X 18 AWG 300V, 4A -40°C to +105°C 7.4mm OD	Industry Standard PVC	1. Brown 2. White 3. Blue 4. Black 5. Gray	<p>7/8"-16UN2</p>

** Lengths in meters. Standard cable lengths are 1, 2, 4, 5, 6, 10 & 15 meters. Consult factory for other lengths.

Standard coupling nut is nickel plated brass, for stainless steel coupling nut add a "-SS" suffix. (e.g. MDCIN-5MFPX-1M becomes MDCIN-5MFPX-1M-SS)

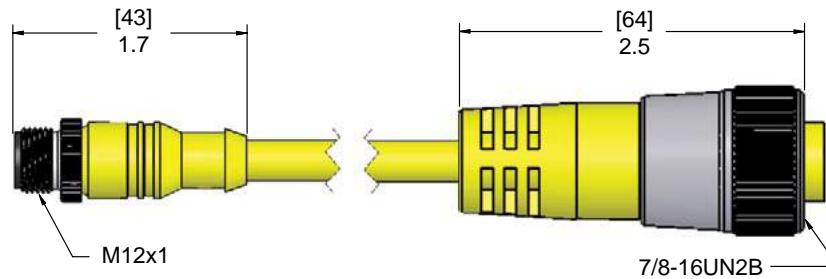

MDC Male - MIN Female Extension