




NAN (M8) Series Cordsets with LEDs

3 Conductor NAN Series Cordsets, 24AWG



Right Angle Female Connectors | Snap-On/Thread-On Style | 30 VDC, 4 amps | IP67 Rating

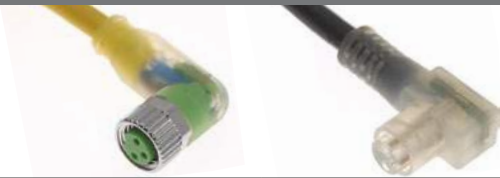


Snap-On Style					
Connector Body Style	Part Number	Cables	Features	Color Code	Female Faceview
	NAN-3FP-**-R-PNP	Black PVC AWM 3 X 24 AWG 30 VDC, 3A -40°C to +105°C 4.5mm OD	Industry Standard PVC LED	1. Brown 2. Not Used 3. Blue 4. Black	
	NAN-3FP-**-R-NPN				
Thread-On Style					
	NAN-T-3FP-**-R-PNP	Yellow PVC AWM 3 X 24 AWG 30 VDC, 3A -40°C to +105°C 4.5mm OD	Industry Standard PVC LED	1. Brown 2. Not Used 3. Blue 4. Black	 M8 x 1
	NAN-T-3FP-**-R-NPN				

** Lengths in meters. Standard cable lengths are 1, 2, 4, 5, 6, 10 & 15 meters. Consult factory for other lengths.


Snap-On

Thread-On

NPN – Normally Open

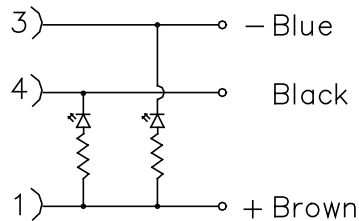

PNP – Normally Open

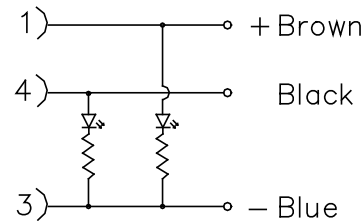

J

NAN (M8) Series