




Ethernet (M12) Series Etherplug Cordsets

8 Conductor Ethernet Series Cordsets, 24/26AWG



Double Ended Cordsets | 60V, 2A | CAT5e | Twisted Pairs | IP67 Rating

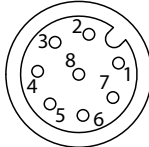

Male Faceview	Cables	Features	Male to Female	Male to Male	Female to Female
 M12 x 1	Teal PVC AWM 8 X 24 AWG 60V, 2A -20°C to +80°C 6.4mm OD	Industry Standard PVC	MDE45-8MFP-**	MDE45-8MMP-**	MDE45-8FFP-**
	Teal PVC AWM With Foil & Braided Shield 8 X 24 AWG 60V, 2A -20°C to +80°C 7.6mm OD	Industry Standard PVC Foil & Braided Shield	MDE45B-8MFP-**	MDE45B-8MMP-**	MDE45B-8FFP-**
	Teal PUR AWM 8 X 24 AWG 60V, 2A -40°C to +80°C 6.3 mm OD	Continuous-Flex Oil and Cutting Fluid Re- sistant Cut Resistant PUR	MDE45P-8MFP-**	MDE45P-8MMP-**	MDE45P-8FFP-**
	Teal PUR With Foil & Braided Shield 8 X 26 AWG 60V, 2A -40°C to +75°C 6.3mm OD	Continuous-Flex Oil and Cutting Fluid Re- sistant Cut Resistant PUR Foil & Braided Shield	MDE45PB-8MFP-**	MDE45PB-8MMP-**	MDE45PB-8FFP-**
	Teal PUR With Foil & Braided Shield 8 X 26 AWG 60V, 2A -40°C to +75°C 6.3mm OD	Continuous-Flex Oil and Cutting Fluid Re- sistant Cut Resistant PUR Foil & Braided Shield to Coupling Nut	MDE45PB-8MFPS-**	MDE45PB-8MMPS-**	MDE45PB-8FFPS-**
	Teal TPE AWM With Foil & Braided Shield 8 X 24 AWG 60V, 2A -40°C to +80°C 7.6mm OD	Continuous-Flex Weld Slag Resistant TPE Foil & Braided Shield	MDE45WB-8MFP-**	MDE45WB-8MMP-**	MDE45WB-8FFP-**
	Teal TPE AWM With Foil & Braided Shield 8 X 24 AWG 60V, 2A -40°C to +80°C 7.6mm OD	Continuous-Flex Weld Slag Resistant TPE Foil & Braided Shield to Coupling Nut	MDE45WB-8MFPS-**	MDE45WB-8MMPS-**	MDE45WB-8FFPS-**

Ethernet Series

L

** Lengths in meters. Standard cable lengths are 1, 2, 4, 5, 6, 10 & 15 meters. Consult factory for other lengths.

Standard coupling nut is nickel plated brass, for stainless steel coupling nut add a "-SS" suffix. (e.g. MDE45-8MFP-1M becomes MDE45-8MFP-1M-SS)



Male Plug



Female Plug