



Ethernet (M12) Series Etherplug Receptacles

4 & 8 Conductor Ethernet Series Panel Mount Adapter




Panel Mount Adapter


M12 4 Pole to RJ45 Panel Mount Adapters				
# of Poles	Female Faceview	Wiring MDE45	Part Number	RJ45 Faceview
<p>4</p> <p>D-Coded</p>	<p>M12 x 1</p> <p>1 = White/Orange (+ TX) 2 = White/Green (+ RX) 3 = Orange (- TX) 4 = Green (- RX)</p>	<p>1 to 1 2 to 3 3 to 2 4 to 6</p>	D24-4MDE45-4FR-RJ45	<p>87654321</p> <p>1 = White/Orange (+ TX) 2 = Orange (- TX) 3 = White/Green (+ RX) 4 = N/C 5 = N/C 6 = Green (- RX) 7 = N/C 8 = N/C</p>
M12 8 Pole to RJ45 Panel Mount Adapters				
<p>8</p> <p>A-Coded</p>	<p>M12 x 1</p> <p>1 = White/Blue 2 = White/Brown 3 = Brown 4 = Orange (-TX) 5 = White/Green (+RX) 6 = White/Orange (+TX) 7 = Blue 8 = Green (-RX)</p>	<p>1 to 5 2 to 7 3 to 8 4 to 2 5 to 3 6 to 1 7 to 4 8 to 6</p>	D24-4MDE45-8FR-RJ45	<p>87654321</p> <p>1 = White/Orange (+ TX) 2 = Orange (- TX) 3 = White/Green (+ RX) 4 = N/C 5 = N/C 6 = Green (- RX) 7 = N/C 8 = N/C</p>

Ethernet Series

L

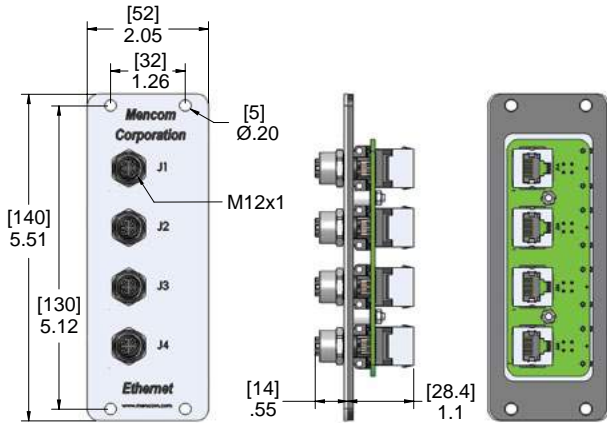

D24-4MDE45-4FR-RJ45

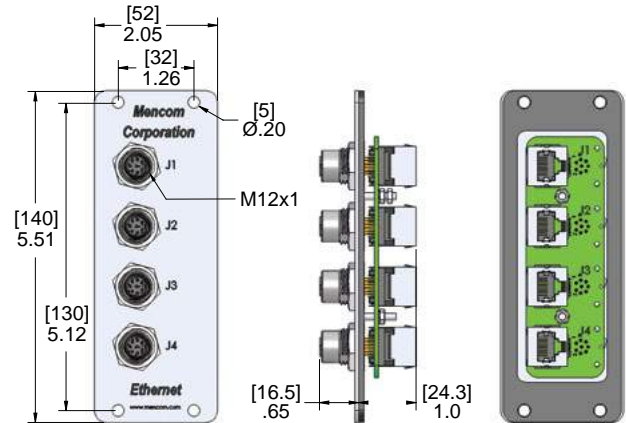

D24-4MDE45-8FR-RJ45

Specifications:

- Plate: Stainless Steel
- M12 Coupling: Nickel Plated Brass
- M12 Insert: Polyamide
- Contacts: Copper Alloy with Gold Plating
- O-Rings: NBR
- Gasket: PVC NBR
- RJ45 Connector: CAT5e
- Mounting Screws: #8 or M4 Screws
- Shielding: Shield connected between M12 Housing and RJ45 Connector
- Temperature: -40°C to +80°C (-40°F to +176°F)

