



Profibus-PA Series MIN/MDC Receptacles


4 Conductor Profibus-PA Series Receptacles, 18AWG




Front Mount Receptacles | 1/2"-14 NPT Threads | 300V, 8A | 300V, 4A | IP67 Rating



Profibus-PA MIN Receptacles 1/2"-14 NPT Threads						
# of Poles	Male Faceview	Color Code	Rating	Wire AWG	Male Receptacles	Female Receptacles
4	<p>7/8"-16UN2</p>	1. Orange(+) 2. N/C 3. Blue(-) 4. Shield	300V 8A	18 AWG	PBIN-4MR-**-SS	PBIN-4FR-**-SS

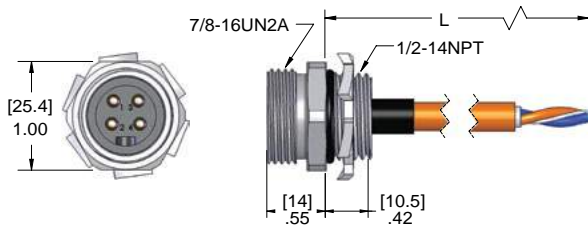

Male Receptacle

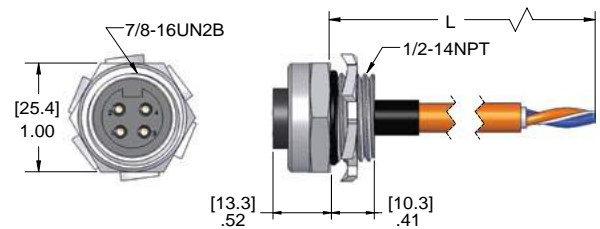

Female Receptacle


Profibus-PA MDC Receptacles 1/2"-14 NPT Threads						
# of Poles	Male Faceview	Color Code	Rating	Wire AWG	Male Receptacles	Female Receptacles
4	<p>M12 x 1</p>	1. Orange(+) 2. N/C 3. Blue(-) 4. Shield	300V 4A	18 AWG	PBDC-4MR-2**-SS	PBDC-4FR-2**-SS

** Lengths in meters.


Lock Nut and O-Ring are included.

Specifications:

- Shell: Stainless Steel
- Insulator: PBIN: Oil Resistant Yellow PVC
PBDC: Polyamide
- Cable: Orange PVC, 2x18 AWG Cable with Foil Shield
- Contacts: Copper Alloy with Gold Plating
- O-ring: NBR
- Lock Nut: Zinc Plated Steel
- Temperature: -40°C to 105°C (-40°F to +221°F)

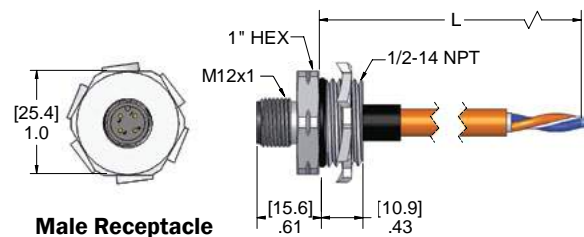

Male Receptacle

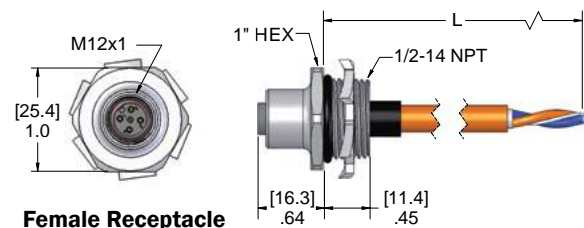

Female Receptacle

Profibus-PA Series

0