





 
 
Profibus-PA Series MIN/MDC Cordsets

4 Conductor Profibus-DP Series MIN/MDC Cordsets, 18AWG

 


Double Ended Cordsets | 300V, 10A | 300V, 4A | IP67 Rating

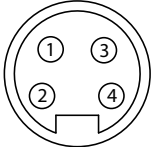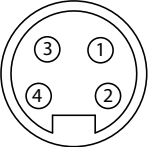

MIN Double Ended Cordsets					
Male Faceview	Part Number	Cables	Features	Color Code	Female Faceview
 7/8"-16UN2	PBIN-4MFPX-**-SS	Orange PVC ITC-ER With Foil Shield 2 X 18 AWG 1 x 22 AWG (Drain) 300V, 10A -40°C to +105°C 7.2mm OD	Crush Proof Industry Standard PVC Stainless Steel Coupling Nut Foil Shield	1. Orange(+) 2. N/C 3. Blue(-) 4. Shield	 7/8"-16UN2
MDC Double Ended Cordsets					
 M12 x 1	PBDC-4MFPX-**-SS	Orange PVC ITC-ER With Foil Shield 2 X 18 AWG 1 x 22 AWG (Drain) 300V, 4A -40°C to +105°C 7.2mm OD	Crush Proof Industry Standard PVC Stainless Steel Coupling Nut Foil Shield	1. Orange(+) 2. N/C 3. Blue(-) 4. Shield	 M12 x 1

** Lengths in meters. Standard cable lengths are 1, 2, 4, 5, 6, 10 & 15 meters. Consult factory for other lengths.



MIN Series Male - Female Extension



MDC Series Male - Female Extension

Profibus-PA Series

0