

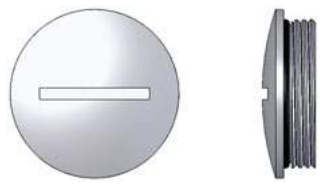


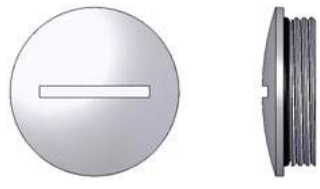
Cable Glands Accessories

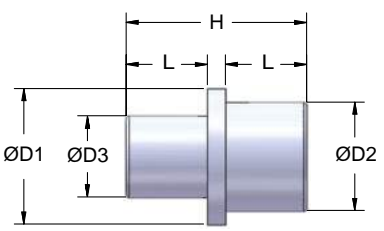
PG Threads Cable Gland Plugs



Blanking Plugs | Blind Plugs | PG Threads | IP68 Rating

Plastic Blanking Plugs					
Part Number		Diameter (mm)	Thread Length (mm)	Thread Type	Style
Gray	Black				
CRB-07PA	CRB-07PA/SW	15	6	PG 07	 <p>Materials: Polystyrene</p>
CRB-09PA	CRB-09PA/SW	19	6	PG 09	
CRB-11PA	CRB-11PA/SW	22	6	PG 11	
CRB-13.5PA	CRB-13.5PA/SW	25	6	PG 13.5	
CRB-16PA	CRB-16PA/SW	27	6	PG 16	
CRB-21PA	CRB-21PA/SW	33	8	PG 21	
CRB-29PA	CRB-29PA/SW	44.5	8	PG 29	
CRB-36PA	CRB-36PA/SW	55.5	10	PG 36	
CRB-42PA	CRB-42PA/SW	62.5	10	PG 42	
CRB-48PA	CRB-48PA/SW	69.5	12	PG 48	

Metal Blanking Plugs				
Part Number	Diameter (mm)	Thread Length (mm)	Thread Type	Style
CRB-07	16	4.5	PG 07	 <p>Materials: Nickel Plated Brass</p>
CRB-09	19	4.5	PG 09	
CRB-11	22	4.5	PG 11	
CRB-13.5	24	6.0	PG 13.5	
CRB-16	26	6.0	PG 16	
CRB-21	32	6.0	PG 21	
CRB-29	39	8.0	PG 29	
CRB-36	50	9.0	PG 36	
CRB-42	57	10.0	PG 42	
CRB-48	64	10.0	PG 48	

Blind Plugs							
Part Number	Thread Type	L	H	D1	D2	D3	Style
PG07-BP	PG 07	6	14	8.5	6.5	5	 <p>Materials: Polyamide</p>
PG09-BP	PG 09	7	16	10	8	6	
PG11-BP	PG 11	8	18	12	10	7	
PG13.5-BP	PG 13.5	9	20	14	12	9	
PG16-BP	PG 16	10	22.5	16	14	12	
PG21-BP	PG 21	12	26.5	20	18	16	
PG29-BP	PG 29	14	30.5	28	25	20	

This insert is used to block a PCG or MCG style cable gland that is not currently in use, but is installed onto a panel. The Blind Plug will enable the cable gland to seal to IP 68. The Blind Plug is NOT for use in the EX style cable glands.