

---

## PLUG, IN-LINE

---



<b>Part No.</b>	ME 360P4W
<b>Description:</b>	60 Amp 125Vac 2 Pole, 3 Wire Plug
<b>Construction:</b>	Watertight IEC IP 67
<b>Approvals:</b>	UL Listed Standards 1682; 1686 CSA Certification to Spec. C22.2 No. 182.1 IEC 60309-1; IEC 60309-2

---

**IEC COLOR CODE:** Yellow

**GROUND SOCKET:** 8 Hour Position Mates with Female in 4 Hour Position.

---

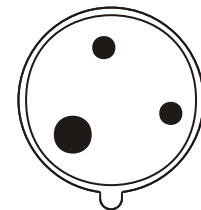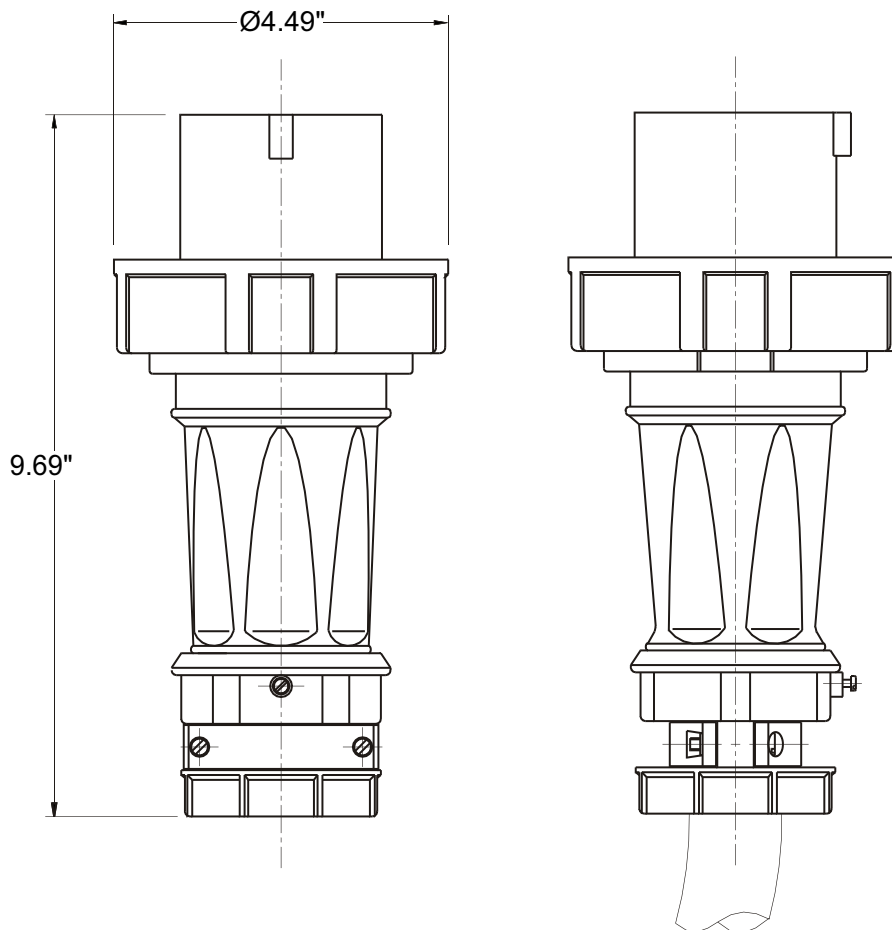

Front View of Plug

Wire Range: #4 - #8 AWG  
Cord Range: .57" - 1.42"  
Threaded Cable Entry: 1 1/2" NPT

Drawing Not to Scale