


## PLUG, IN-LINE

<b>Part No.</b>	ME 530P6W-60813
<b>Description:</b>	30 Amp 3P+N+G 200/380V - 240/415Vac, 5 Wire 32 Amp 3P+N+G 200/346V - 240/415Vac, 5 Wire
<b>Construction:</b>	Watertight Plug - IEC IP 67
<b>Approvals:</b>	IEC 60309-1; IEC 60309-2; VDE; cULus Pending

**IEC COLOR CODE:** Red

**GROUND SOCKET:** 6 Hour Position Mates with Female in 6 Hour Position.

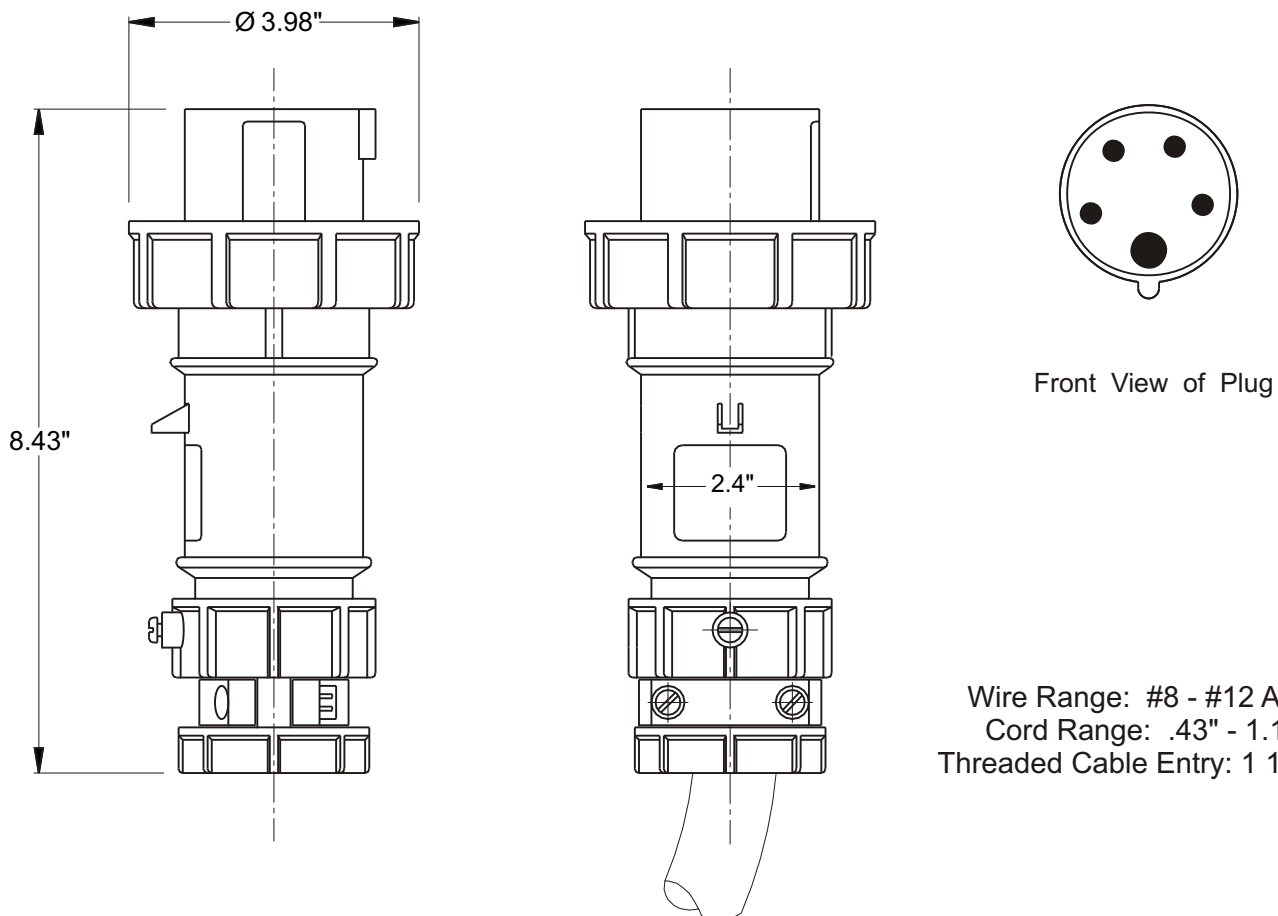

Front View of Plug

Wire Range: #8 - #12 AWG  
Cord Range: .43" - 1.12"  
Threaded Cable Entry: 1 1/4" NPT

Drawing Not to Scale