
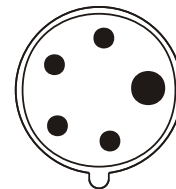
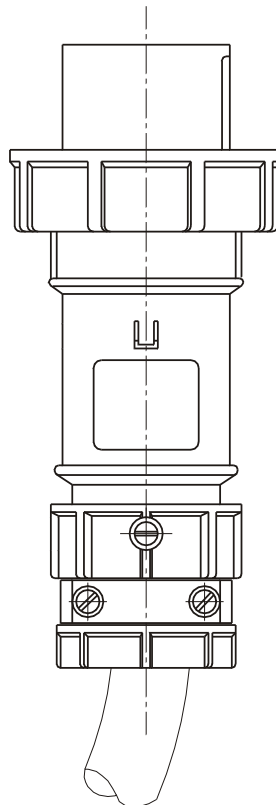


## PLUG, IN-LINE

<b>Part No.</b>	ME 530P9W
<b>Description:</b>	30 Amp 3 Y 120/208Vac 4 Pole, 5 Wire Plug
<b>Construction:</b>	Watertight IEC IP 67
<b>Approvals:</b>	UL Listed Standards 1682; 1686 CSA Certification to Spec. C22.2 No. 182.1 IEC 60309-1; IEC 60309-2

**IEC COLOR CODE:** Blue

**GROUND SOCKET:** 3 Hour Position Mates with Female in 9 Hour Position.

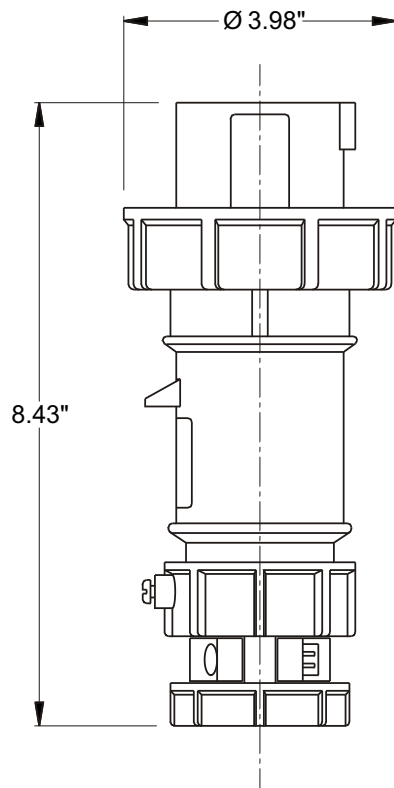

Front View of Plug

Wire Range: #8 - #12 AWG  
Cord Range: .43" - 1.12"  
Threaded Cable Entry: 1 1/4" NPT

Drawing Not to Scale