

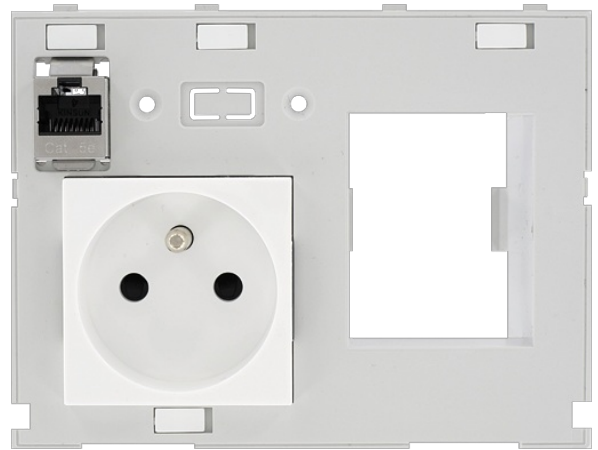
**MODLINK MSDD DBL COMBI INSERT FRANCE**

1xRJ45 fem./fem. + RCD opening

1x France (UTE-NF) white

1x RJ45, 8-pole metal, CAT5e (female/female)

1x FI cut-out

**Illustration**

Product may differ from Image

**General data**

Dimensions H×W×D 88×116×70 mm

**RJ45**

Operating voltage (UL Rating) max. 30 V AC/42.4 V DC

Operating current (UL Rating) max. 175 mA

Connection front side RJ45

Connection rear side RJ45

Locking of ports Snap In

Specification CAT5e, Class D, 100 MHz, (EN 50173-1)

**Shielding plate**

Connection Threaded hole M4

Tightening torque 0.9 Nm ±0.1

**France (UTE-NF)**

Operating voltage 250 V AC

Operating current 16 A

No. of poles 2 + PE

Connection Screw terminals: max. 2× 4 mm<sup>2</sup> (AWG 12)**Commercial data**

country of origin DE

customs tariff number 85366990

EAN 4048879384513

eClass 27189217

Packaging unit 1