

**MODLINK MSDD DBL COMBI INSERT FRANCE**

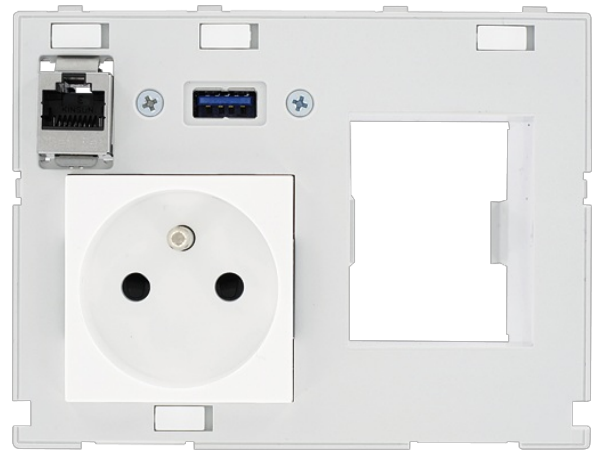
1xRJ45+USB-A + RCD opening

1× France (UTE-NF) white

1× RJ45, 8-pole metal, CAT5e (female/female)

1× USB 3.0 (female/female) form A

1× FI cut-out

**Illustration**

Product may differ from Image

**General data**

Dimensions H×W×D	88×116×70 mm
------------------	--------------

**RJ45**

Operating voltage (UL Rating)	max. 30 V AC/42.4 V DC
Operating current (UL Rating)	max. 175 mA
Connection front side	RJ45
Connection rear side	RJ45
Locking of ports	Snap In
Specification	CAT5e, Class D, 100 MHz, (EN 50173-1)

**Shielding plate**

Connection	Threaded hole M4
Tightening torque	0.9 Nm ±0.1

**USB**

Operating voltage	48 V AC/DC
Operating voltage (UL Rating)	max. 30 V AC/42.4 V DC
Operating current	1.5 A
Locking of ports	Snap In
Specification	USB: 3.0 (max. 5 Gbit/s)

**France (UTE-NF)**

Operating voltage	250 V AC
Operating current	16 A
No. of poles	2 + PE
Connection	Screw terminals: max. 2× 4 mm <sup>2</sup> (AWG 12)

**Commercial data**

country of origin	DE
customs tariff number	85366990
EAN	4048879446341
eClass	27189217
Packaging unit	1