

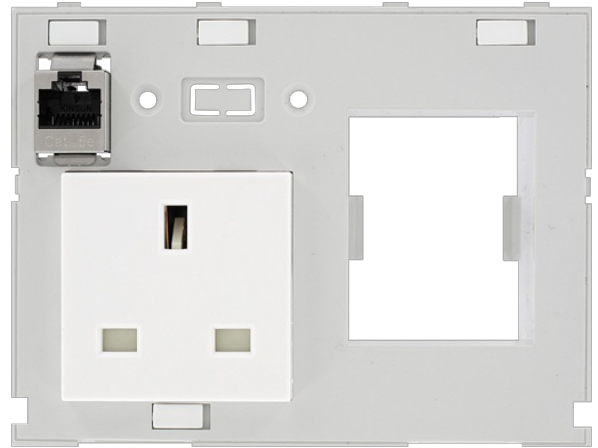
MODLINK MSDD DBL COMBI INSERT GREAT BRITAIN

1xRJ45 fem./fem. + RCD opening

1 × Great Britain (BS)

1 × RJ45, 8-pole metal, CAT5e (female/female)

1 × FI cut-out

Illustration

Product may differ from Image

General data

Dimensions H×W×D 88×116×70 mm

RJ45

Operating voltage (UL Rating) max. 30 V AC/42.4 V DC

Operating current (UL Rating) max. 175 mA

Connection front side RJ45

Connection rear side RJ45

Locking of ports Snap In

Specification CAT5e, Class D, 100 MHz, (EN 50173-1)

England (BS)

Operating voltage 250 V AC

Operating current 13 A

No. of poles 2 + PE

Connection Screw terminals: max. 2× 4 mm² (AWG 12)**Commercial data**

country of origin DE

customs tariff number 85366990

EAN 4048879384506

eClass 27189217

Packaging unit 1