

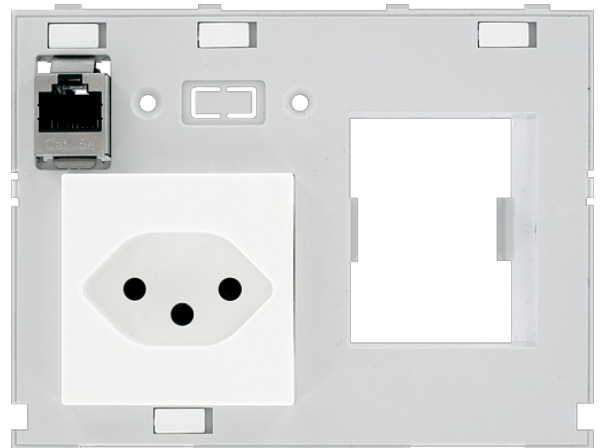
**MODLINK MSDD DBL COMBI INSERT SWITZERLAND**

1xRJ45 fem./fem. + RCD opening

1× Swiss

1× RJ45, 8-pole metal, CAT5e (female/female)

1× FI cut-out

**Illustration**

Product may differ from Image

**General data**

Dimensions H×W×D 88×116×70 mm

**RJ45**

Operating voltage (UL Rating) max. 30 V AC/42.4 V DC

Operating current (UL Rating) max. 175 mA

Connection front side RJ45

Connection rear side RJ45

Locking of ports Snap In

Specification CAT5e, Class D, 100 MHz, (EN 50173-1)

**Swiss**

Operating voltage 250 V AC

Operating current 10 A

No. of poles 2 + PE

Connection Spring clamp terminals: max. 2× 1.5 mm<sup>2</sup> (AWG 16)**Commercial data**

country of origin HU

customs tariff number 85366990

EAN 4048879384612

eClass 27189217

Packaging unit 1