

**MIUW ANALOG COUPLER COMPONENT**

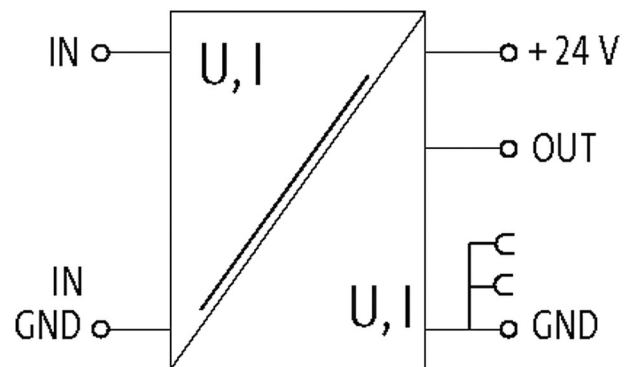
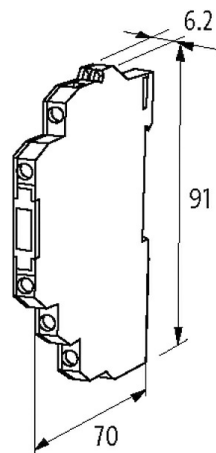
IN: 0..20 mA - OUT: 0..10 V

INPUT: 0...20 mA

OUTPUT: 0...10 V DC, 20 mA

Screw terminals

Input and output galvanically separated

**Illustration**

Product may differ from Image

**General data**

The information in this brochure has been compiled with the utmost care.

Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 10/20

Test isolation voltage	1.5 kV
Mounting method	DIN-rail mountable (EN 60715)
Temperature range	-25...+50 °C (storage temperature -40...+80 °C)
Dimensions H×W×D	91 × 6.2 × 70 mm

**Technical Data**

Operating voltage	24 V DC ±20%, smoothed
Operating current	50...70 mA
Tolerance	max. 0.5%
Frequency	max. 500 Hz

**Current input signals**

Load	approx. 250 Ω
------	---------------

**Voltage output signals**

Load	max. 25 mA
------	------------

**Current outputs**

Load	max. 500 Ω
------	------------

**Description**

Functional description	The Murrelektronik analog converters convert standard signal formats (0...10 V, 0...20 mA, 4...20 mA) galvanically separated into one of these signal formats. Due to an integrated current limiter the output is short-circuit and overload protected. Module
------------------------	--

**Commercial data**

country of origin	CZ
customs tariff number	85437090
EAN	4048879028462
eClass	27210990
Packaging unit	1