

MIW ANALOG COUPLER COMPONENT

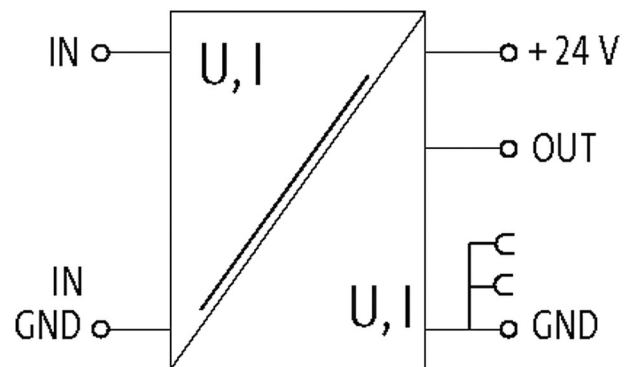
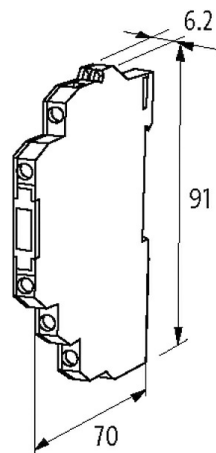
IN: 0(4)..20 mA - OUT: 0(4)..20 mA

INPUT: 0...20 mA

OUTPUT: 0...20 mA

Screw terminals

Input and output galvanically separated

Illustration

Product may differ from Image

General data

Test isolation voltage	1.5 kV
Mounting method	DIN-rail mountable (EN 60715)
Temperature range	-25...+50 °C (storage temperature -40...+80 °C)
Dimensions H×W×D	91 × 6.2 × 70 mm

Technical Data

Operating voltage	24 V DC ±20%, smoothed
Operating current	50...70 mA
Tolerance	max. 0.5%
Frequency	max. 500 Hz

Current input signals

Load	approx. 250 Ω
------	---------------

Voltage output signals

Load	max. 25 mA
------	------------

Current outputs

Load	max. 500 Ω
------	------------

Description

Functional description	The Murrelektronik analog converters convert standard signal formats (0...10 V, 0...20 mA, 4...20 mA) galvanically separated into one of these signal formats. Due to an integrated current limiter the output is short-circuit and overload protected. Module
------------------------	--

Commercial data

country of origin	CZ
customs tariff number	85437090
EAN	4048879028431
eClass	27210990
Packaging unit	1