
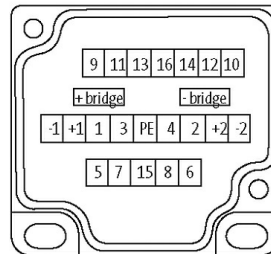


MVP12, 8XM12, MOSA, PLUG. CAP SCT.


With potent. sep.

- pluggable connection cap
- PIN 1: +24 V or PE selectable by plug links
- Potential separation as option
- with LED for digital PNP-signals 24 V DC
- quick connection elements included
- Further cable lengths on request.

Illustration

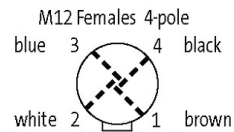

for 2 signals per port

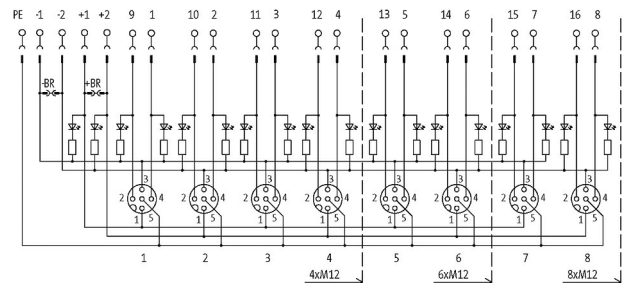

Product may differ from Image

Contact Layout

PIN 1	(+)
PIN 2	(NC)/(S2)
PIN 3	(-)
PIN 4	(NO)/(S1)
PIN 5	(Earth)

LED display LED (green): Power / LED (yellow): (S1/S2)

General data

Temperature range	-20...+80 °C
Dimensions H×W×D	43×50.2×170 mm

Technical Data

Operating voltage	24 V DC
Signal per port	2
Operating current per contact	max. 4 A
Total current	max. 2× 8 A
Connection cross section	0.25...0.5 mm ²
Housing	Plastic, flame retardant
Protection	IP67 inserted and tightened (EN 60529)
Locking of ports	Cap nut

Commercial data

country of origin	DE
customs tariff number	85369010
EAN	4048879057646
eClass	27279219
Packaging unit	1