

MVP12, 4XM12, MOSA, PLUGGABLE CABLE

5.0m PUR-JB 8x0,34+5x0,75

4-way, 5-pole, MOSA



PUR/PVC (UL/CSA)

5.0 m


potentially separated

with LED for digital PNP-signals 24 V DC

Illustration

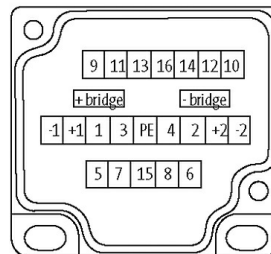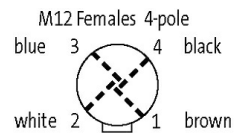

for 2 signals per port

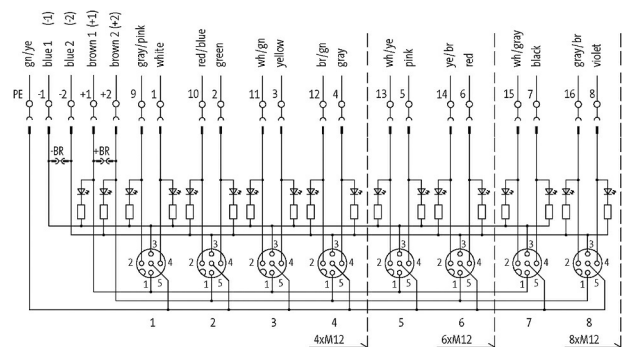

Product may differ from Image

Contact Layout

PIN 1	(+)
PIN 2	(NC)/(S2)
PIN 3	(-)
PIN 4	(NO)/(S1)

PIN 5	(Earth)
LED display	LED (green): Power / LED (yellow): (S1/S2)

General data

Temperature range	-20...+80 °C
Dimensions H×W×D	43×50.2×122 mm

Cables

Cable number	374
No./diameter of wires	8 × 0.34 + 5 × 0.75 mm ²
Wire isolation	PVC
C-track properties	1.5 Mio.
Jacket Color	gray
Material (jacket)	PUR/PVC
Outer Ø	9.2 mm ±5%
Bend radius (fixed)	10× outer Ø
Bend radius (moving)	12× outer Ø
Temperature range (fixed)	-30...+80 °C
Temperature range (mobile)	-30...+80 °C
Color (jacket)	gray

Technical Data

Operating voltage	24 V DC
Operating current per contact	max. 4 A
Total current	max. 2 × 8 A
Signal per port	2
Connection cross section	0.25...0.5 mm ²
Housing	Plastic, flame retardant
Protection	IP67 inserted and tightened (EN 60529)
Locking of ports	Cap nut

Commercial data

country of origin	DE
customs tariff number	85444290
EAN	4048879057639
eClass	27279219
Packaging unit	1