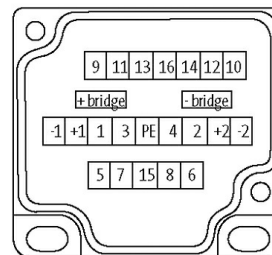
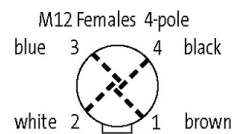


MVP12, 4XM12, MOSA, CON. CAP

With potent. sep.

pluggable connection cap
 Potential separation as option
 with LED for digital PNP-signals 24 V DC
 quick connection elements included
 Further cable lengths on request.
 Plastic housings with good resistance against chemicals and oils.

Illustration

for 2 signals per port

Product may differ from Image

Contact Layout

PIN 1	(+)
PIN 2	(NC)/(S2)
PIN 3	(-)
PIN 4	(NO)/(S1)
PIN 5	(Earth)
LED display	LED (green): Power / LED (yellow): (S1/S2)

General data

Temperature range	-20...+80 °C
Dimensions H×W×D	43×50.2×122 mm

Technical Data

Operating voltage	24 V DC
Signal per port	2
Operating current per contact	max. 4 A
Total current	max. 2× 8 A
Connection cross section	0.25...0.5 mm ²
Locking of ports	Cap nut
Protection	IP67 inserted and tightened (EN 60529)
Housing	Plastic, flame retardant

Commercial data

country of origin	CZ
customs tariff number	85369010
EAN	4048879057509
eClass	27279219
Packaging unit	1