

RMMDUE 11/230 V AC INPUT RELAY

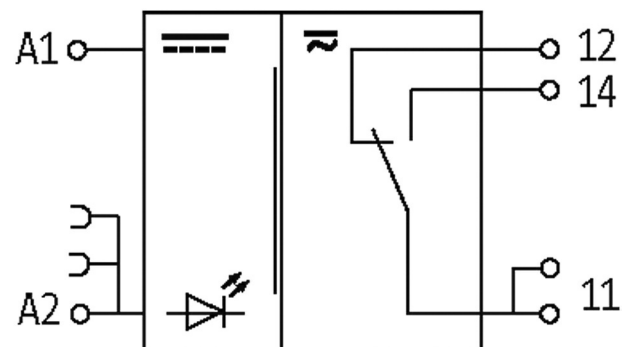
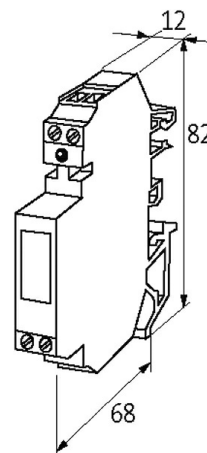
IN: 230 VAC/DC - OUT: 250 VAC/DC / 5 A

1 relay; 1 NO/NC contact

5 A

230 V AC

with minus plug link

Illustration

Product may differ from Image

Input

Connection voltage - current	230 V AC/DC (195...253 V AC/DC) - 4.5 mA
------------------------------	--

LED display	LED (yellow)
-------------	--------------

Output

Switching voltage	max. 250 V AC/DC
-------------------	------------------

Switching current per output	max. 5 A
------------------------------	----------

Min. load current	1 mA
-------------------	------

Power rating (voltage dependent)	max. 1500 VA/180 W
----------------------------------	--------------------

Switching frequency	max. 15 Hz
---------------------	------------

Contact material	Ag Ni 0.15 hv; Ag hv
------------------	----------------------

Energize/release/contact bounce time	10/10/1 ms
--------------------------------------	------------

Utilization category

AC-1	5 A (24/110/230 V AC)
------	-----------------------

AC-15	4 A (24/110/230 V AC)
-------	-----------------------

DC-13	2 A (24 V DC); 0.25 A (110 V DC); 0.1 A (230 V DC)
-------	--

General data

Mech./ elect. life	100 000 000 switching cycles/load dependent
--------------------	---

Test isolation voltage	4.0 kV
------------------------	--------

Mounting method	DIN-rail mountable TH35 or G32 (EN 60715)
-----------------	---

Temperature range	-20...+60 °C
-------------------	--------------

Dimensions H×W×D	82×12×68 mm
------------------	-------------

Commercial data

country of origin	CZ
-------------------	----

customs tariff number	85364900
-----------------------	----------

EAN	4048879027748
-----	---------------

eClass	27371001
--------	----------

Packaging unit	1
----------------	---