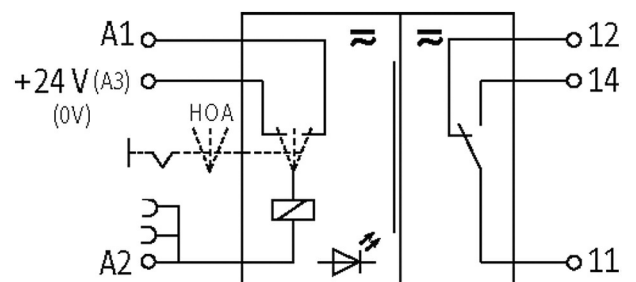
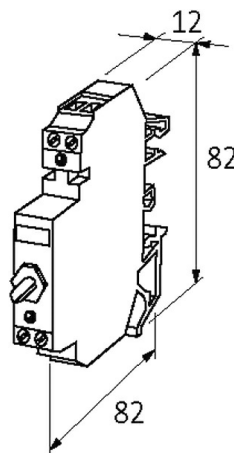


RMMDUH-ST 11/24 OUTPUT RELAY WITH TOGGLE SWITCH

IN: 24 VAC/DC - OUT: 250 VAC/DC / 8 A

1 relay; 1 NO contact
 8 A
 24 V AC/DC
 with minus plug link
 Screw terminals

Illustration

Product may differ from Image

Input

Connection voltage - current	24 V AC/DC (19.2...28 V AC/DC) - 16 mA
------------------------------	--

Plug link (supplied)	Art-No. 90960
----------------------	---------------

LED display	LED (red)
-------------	-----------

Output

Switching voltage	max. 250 V AC/DC
-------------------	------------------

Switching current per output	max. 8 A
------------------------------	----------

Min. load current	100 mA
-------------------	--------

Power rating (voltage dependent)	max. 2000 VA/240 W
----------------------------------	--------------------

Switching frequency	max. 15 Hz
---------------------	------------

Contact material	Ag Ni
------------------	-------

Energize/release/contact bounce time	10/10/2 ms
--------------------------------------	------------

Utilization category

AC-1	8 A (24/110/230 V AC)
------	-----------------------

AC-15	3 A (24/110/230 V AC)
-------	-----------------------

DC-13	1.5 A (24 V DC); 0.3 A (110 V DC); 0.15 A (230 V DC)
-------	--

General data

Mech./ elect. life	30 000 000 switching cycles/load dependent
--------------------	--

Test isolation voltage	3.0 kV
------------------------	--------

Mounting method	DIN-rail mountable TH35 or G32 (EN 60715)
-----------------	---

Temperature range	-20...+50 °C
-------------------	--------------

Dimensions H×W×D	82×12×82 mm
------------------	-------------

Commercial data

country of origin	CZ
-------------------	----

customs tariff number	85364900
-----------------------	----------

EAN	4048879027724
-----	---------------

eClass	27371001
--------	----------

Packaging unit	1
----------------	---