

RM-21/24V AC/DC KL.BZ.N.EN OUTPUT RELAY

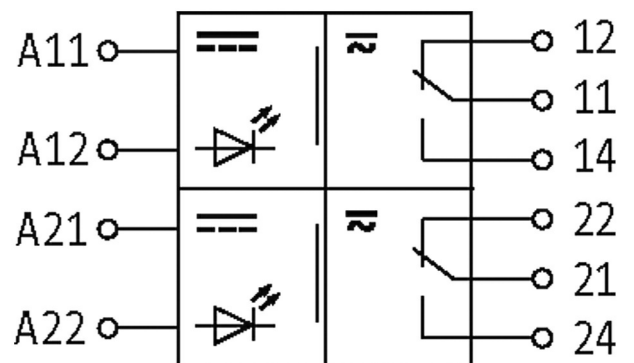
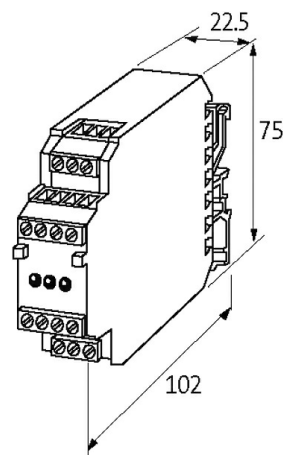
IN: 24 VAC/DC - OUT: 250 VAC/DC / 5 A

2 relays; each 1 NO/NC contact

8 A

24 V DC

Screw terminals

Illustration

Product may differ from Image

Input

Connection voltage - current	24 V AC/DC (19.2...30 V AC/DC) - 10 mA
------------------------------	--

LED display	LED (red)
-------------	-----------

Output

Switching voltage	max. 250 V AC/DC
-------------------	------------------

Switching current per output	max. 8 A
------------------------------	----------

Min. load current	100 mA
-------------------	--------

Power rating (voltage dependent)	max. 1250 VA/240 W
----------------------------------	--------------------

Switching frequency	max. 0.1 Hz (with load)
---------------------	-------------------------

Contact material	Ag Sn O ₂
------------------	----------------------

Energize/release/contact bounce time	10/10/2 ms
--------------------------------------	------------

Utilization category

AC-1	8 A (24/110/230 V AC)
------	-----------------------

AC-15	3 A (24/110/230 V AC)
-------	-----------------------

DC-13	1.5 A (24 V DC); 0.3 A (110 V DC); 0.15 A (230 V DC)
-------	--

General data

Mech./ elect. life	20 000 000 switching cycles/load dependent
--------------------	--

Test isolation voltage	4.0 kV
------------------------	--------

Mounting method	DIN-rail mountable TH35 or G32 (EN 60715)
-----------------	---

Temperature range	-20...+50 °C
-------------------	--------------

Dimensions H×W×D	75×22.5×102 mm
------------------	----------------

Commercial data

country of origin	CZ
-------------------	----

customs tariff number	85364900
-----------------------	----------

EAN	4048879027595
-----	---------------

eClass	27371001
--------	----------

Packaging unit	1
----------------	---